
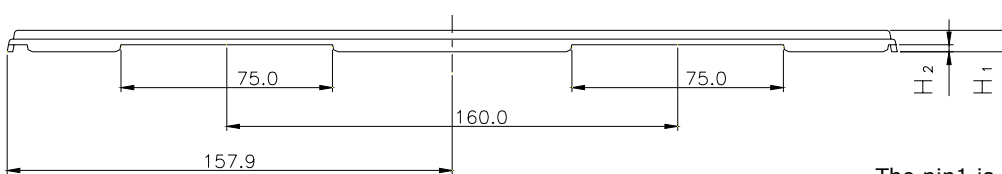



CUSTOM TRAY

| Tray Code | RENESAS Code | Previous Code |
|-----------|--------------|--------------------|
| PT766C | PRQP0136GA-A | FP-136 / FP-136V |
| | PRQP0168JA-A | FP-168 / FP-168V |
| | PRQP0168JB-A | FP-168B / FP-168BV |

Unit:mm

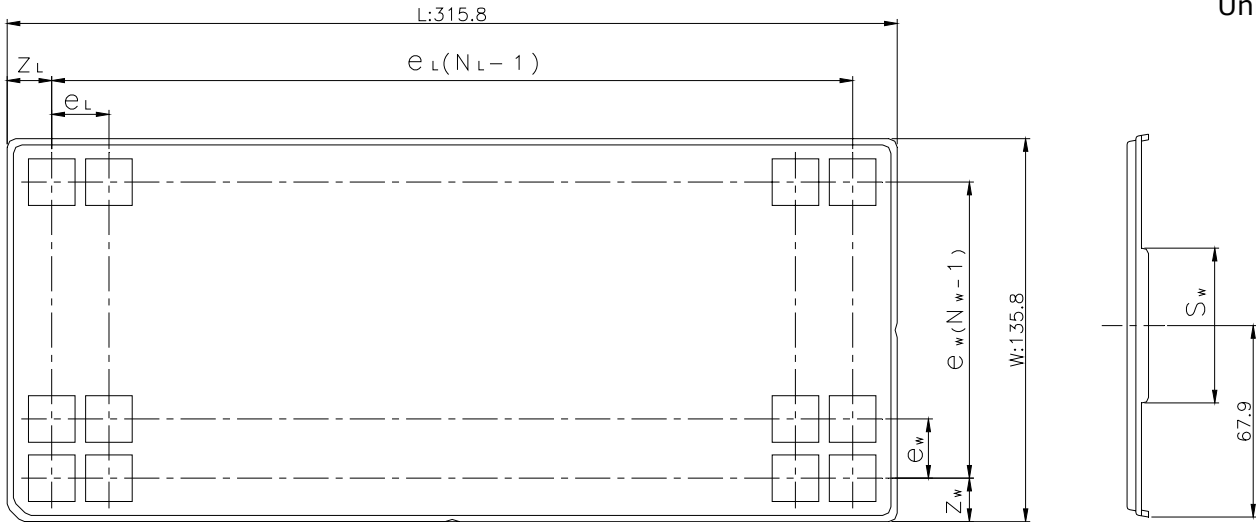

The pin1 is located in the hatching portion

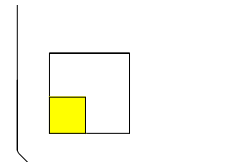

| | | |
|----------------------------------|-------|---|
| Position dimension of cells (mm) | Z_W | 27.1 |
| | Z_L | 25.25 |
| | e_w | 40.8 |
| | e_L | 37.9 |
| | S_w | 55 |
| Thickness (mm) | H_1 | 8.7 |
| | H_2 | 3 |
| Number of cells | N_W | 3 |
| | N_L | 8 |
| Maximum storage No. IC/Tray | | 24 |
| Maximum storage No. IC/Inner box | | 240 |
| Material | | Carbon PPE |
| Surface resistance | | Less than $1 \times 10^{11} \Omega / \square$ |
| Heat resistant temperature | | 125°C24h |
| Packing form | | Dry pack |