

A-D accuracy 10bit

Type: R5F21248SNFP (Topr=-20 to 85degrees C)

R5F21248SDFP (Topr=-40 to 85degrees C)

Topr=-40 degrees C

AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF




AVcc=Vref=5.120V

Xin=20MHz ϕ_{AD} =10MHz sample and hold=on Repeat mode

Absolute accuracy

-2.61LSB

Prepared on Oct. 20, 2006

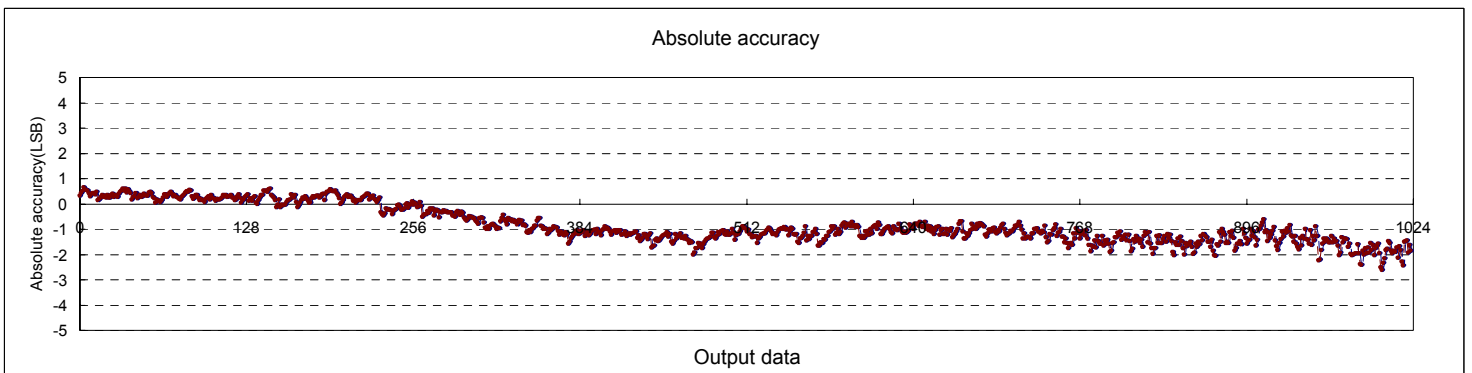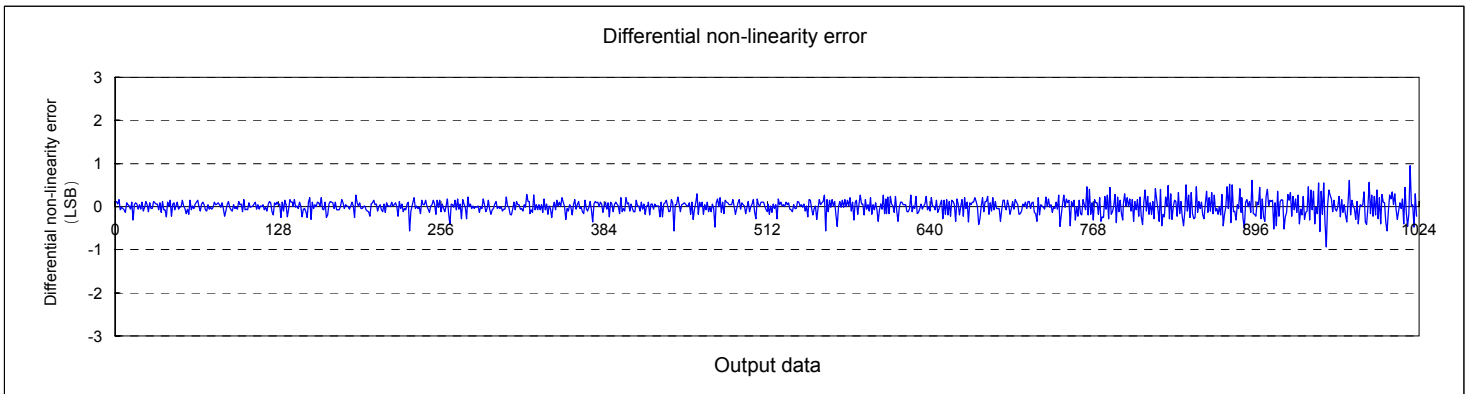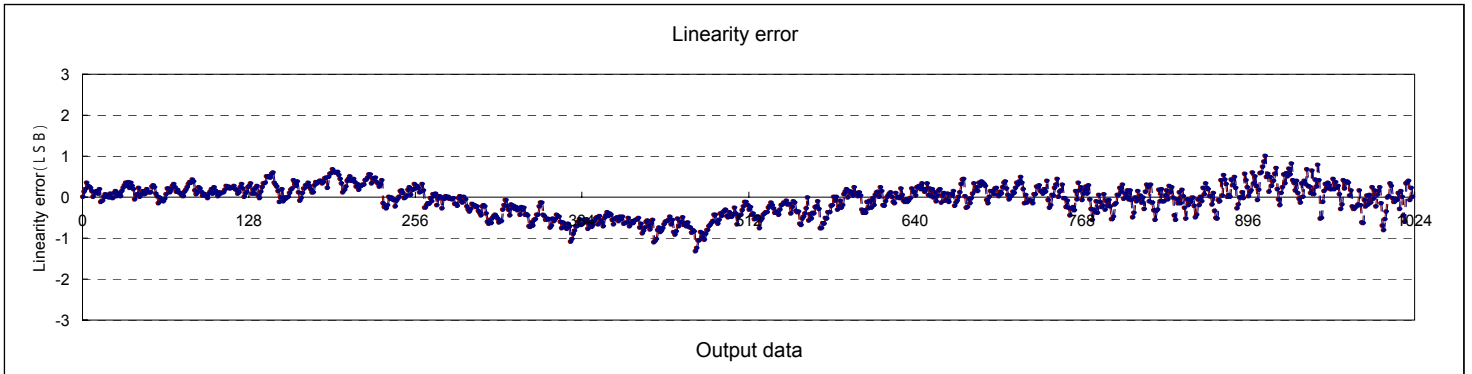

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.