


# Icc vs Topr (High-speed clock mode)

Prepared on Oct. 20, 2006

R5F21248SNFP(Topr=-20 to 85degrees C)  
R5F21248SDFP(Topr=-40 to 85degrees C)  
Vcc=5V  
XIN (square wave)  
High-speed on-chip oscillator off  
Low-speed on-chip oscillator on = 125 kHz

- XIN=20MHz no division
- XIN=20MHz divide by 8
- XIN=10MHz no division
- XIN=10MHz divide by 8

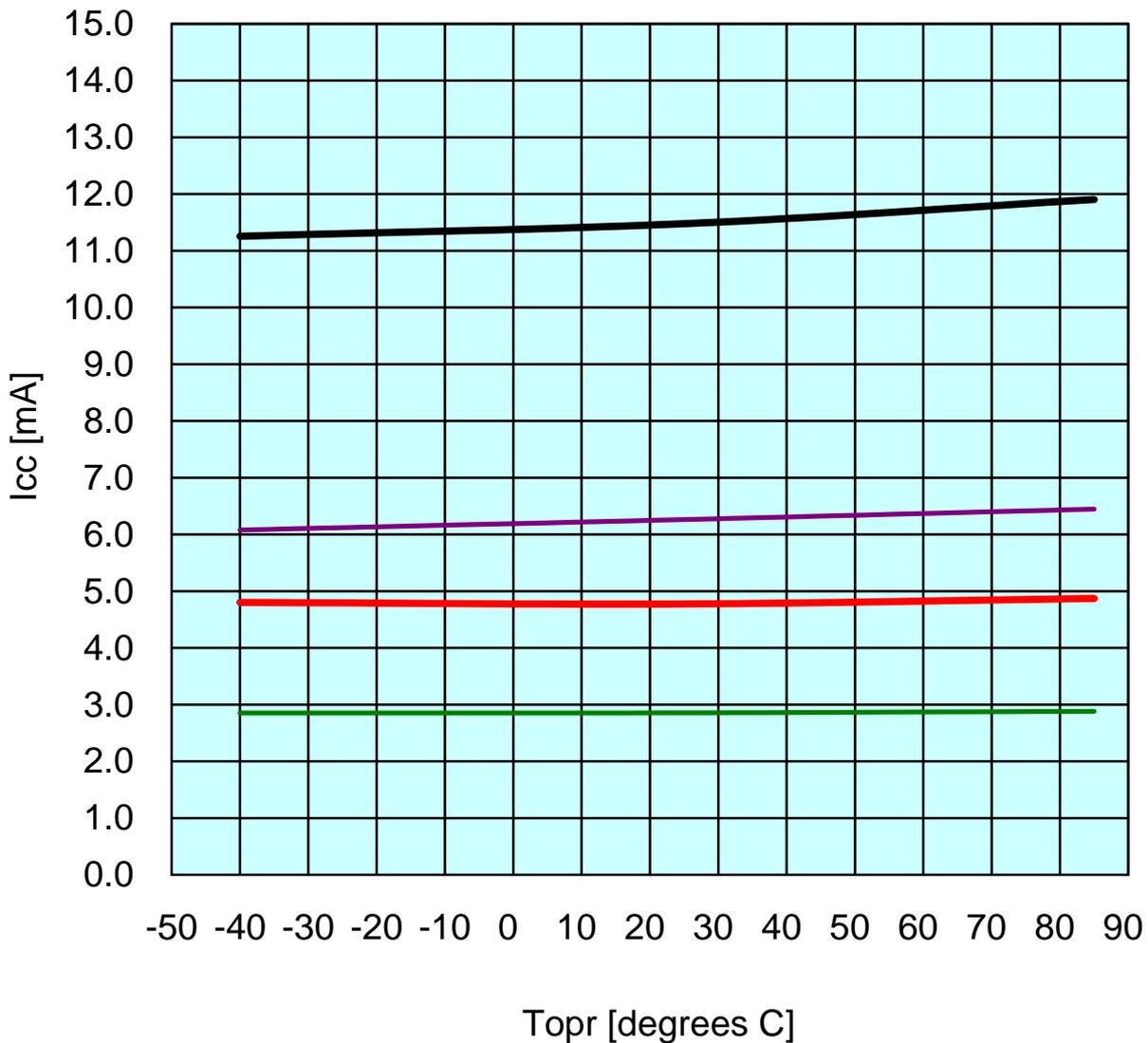

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.