

# IoL vs VoL

(P2\_0-P2\_7 Drive Capacity=Low)

Prepared on Oct. 20, 2006


R5F21248SNFP (Topr=-20 to 85degrees C)

R5F21248SDFP (Topr=-40 to 85degrees C)

Topr=25degrees Celsius

Vcc=5V, 3V, 2.2V

— Vcc=5V — Vcc=3V — Vcc=2.2V

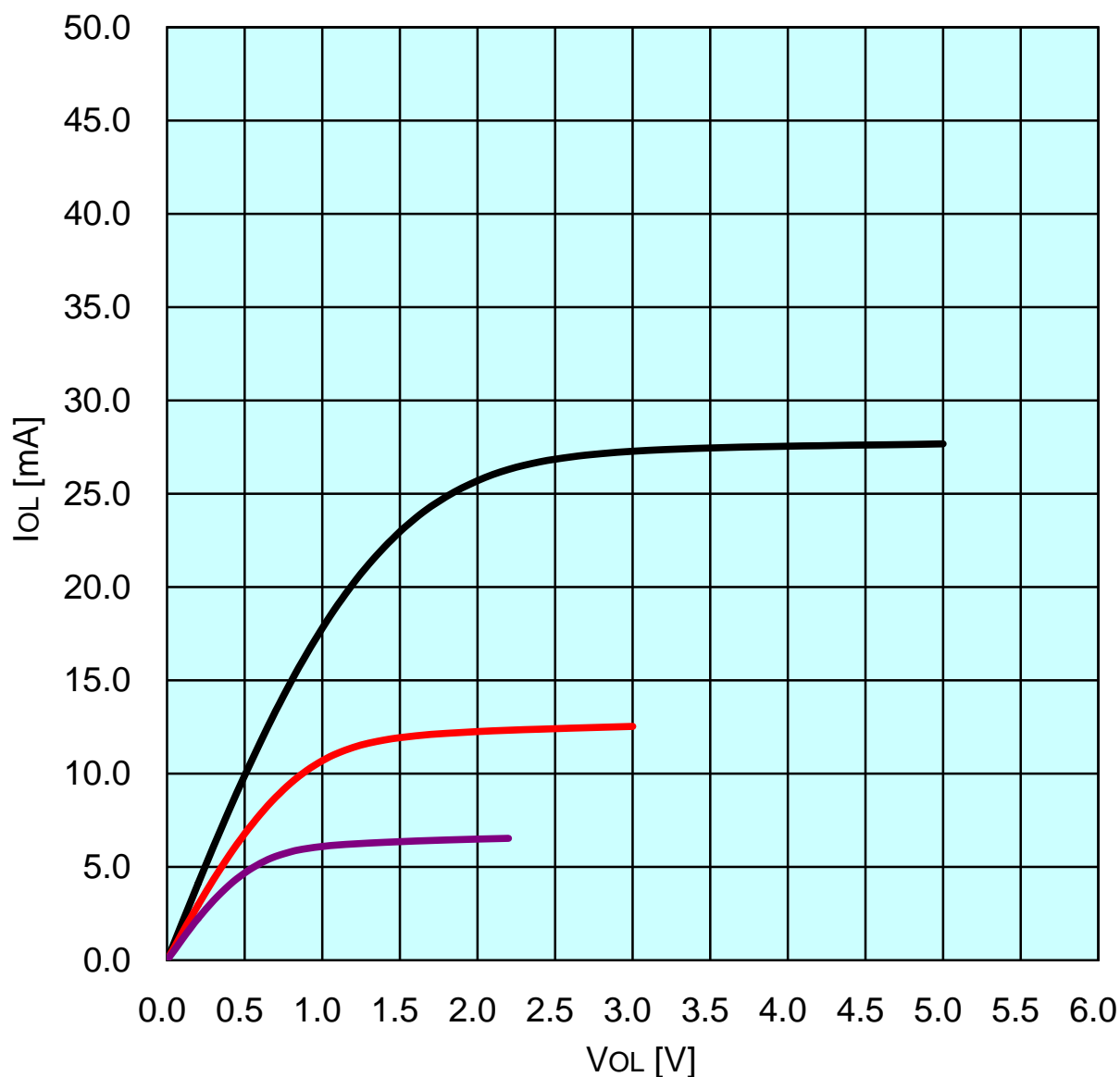

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.