

# IOL vs VOL


(P2\_0-P2\_7 Drive Capacity=Low)

Prepared on Oct. 20, 2006

R5F21248SNFP (Topr=-20 to 85degrees C)  
R5F21248SDFP (Topr=-40 to 85degrees C)  
Vcc=5V

— 85degreeC  
— -40degreeC

— 25degreeC

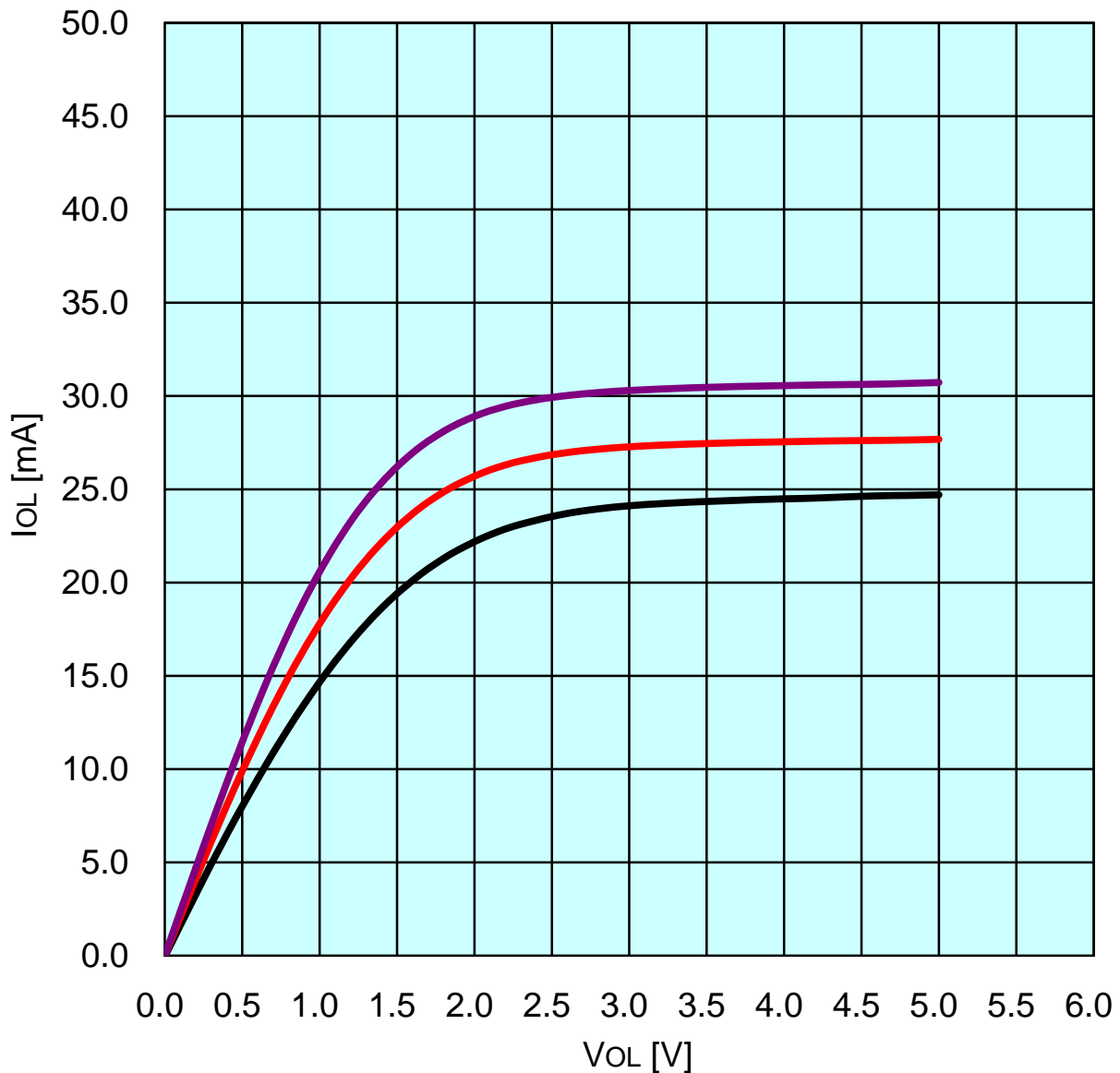

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.