

VOH VS VCC

(P0_0-P0_7,P1_0-P1_7,P3_0,P3_1,
P3_3-P3_5,P3_7,P4_2-P4_5,P6_0-P6_7)

Prepared on Oct. 20, 2006

R5F21248SNFP (Topr=-20 to 85degrees C)

R5F21248SDFP (Topr=-40 to 85degrees C)


Topr=25degrees C

IOH=-5mA, -1mA, -200uA

— IOH=-5mA

— IOH=-1mA

— IOH=-200uA

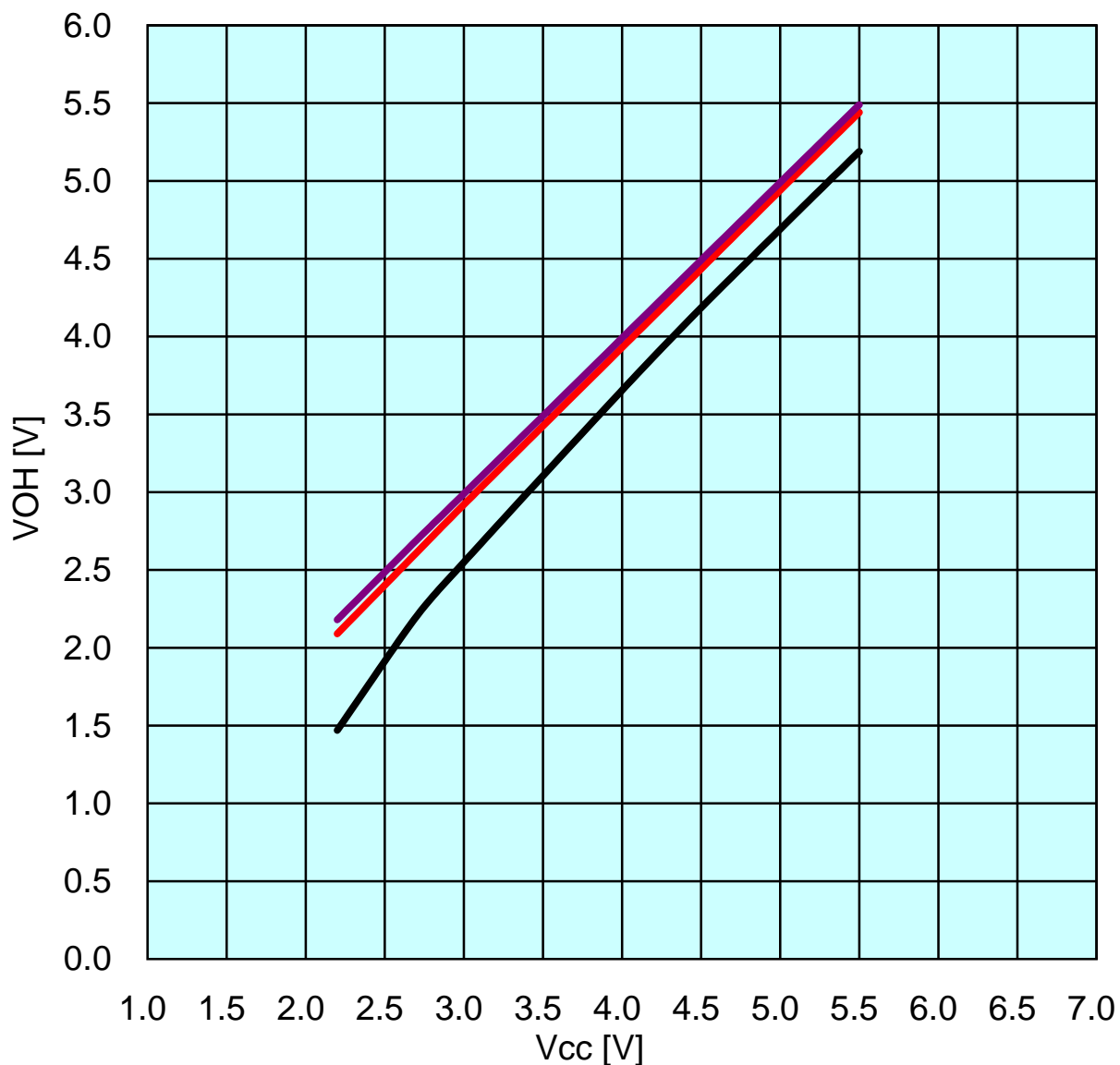

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.