

VOL vs Vcc

(P2_0-P2_7 Drive Capacity=High)


Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)
R5F21258SDFP(Topr=-40 to 85degrees C)
Topr=25degrees C
IOL=20mA, 5mA, 2mA

— IOL=20mA

— IOL=5mA

— IOL=2mA

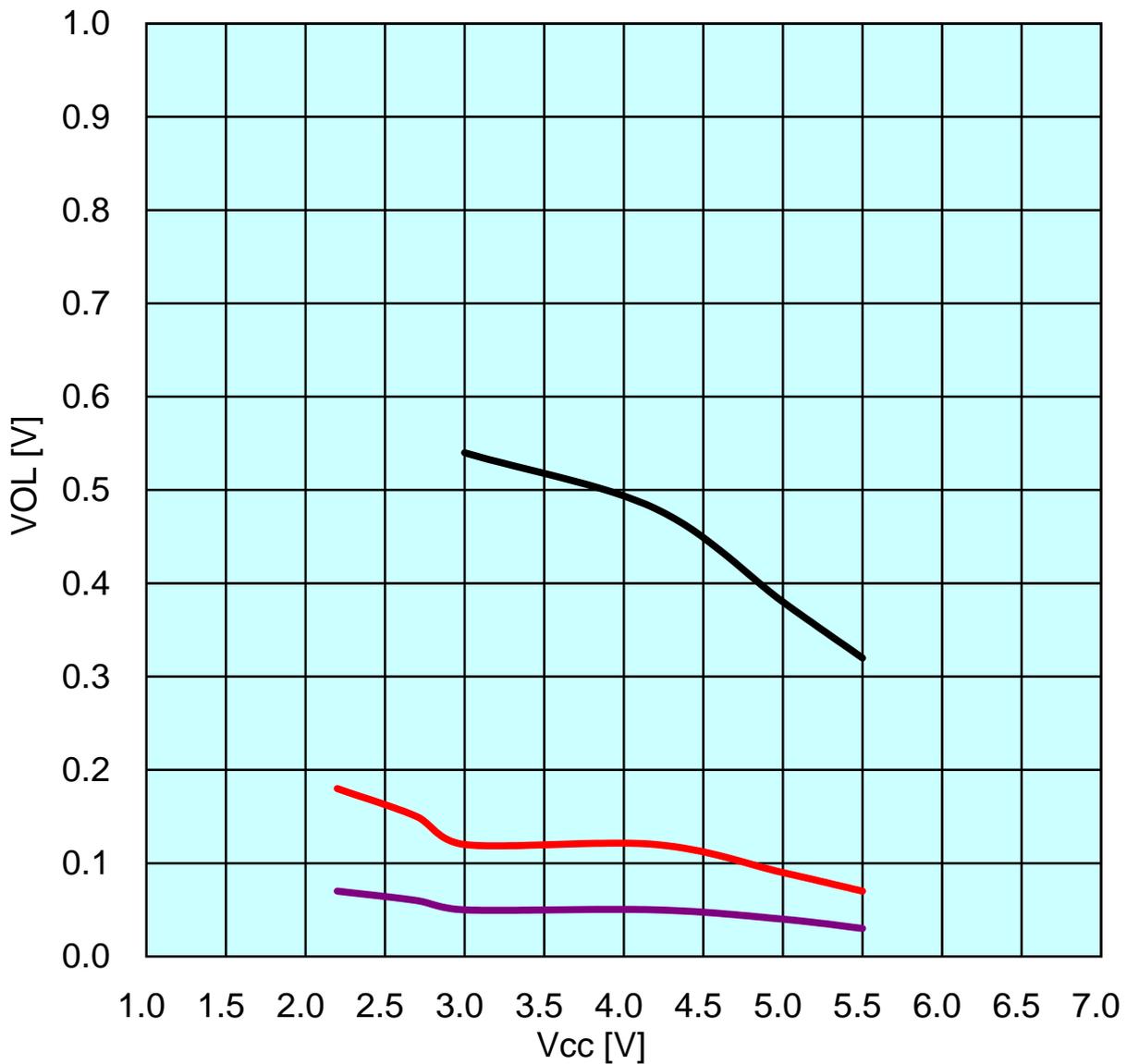

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.