

A/D accuracy 10bit

R8C/26-27 Group

Topr = 25 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=2.252V

Xin=10MHz φAD=5MHz sample and hold=on Repeat mode

Absolute accuracy
-1.42LSB

Prepared on Sep. 07, 2007

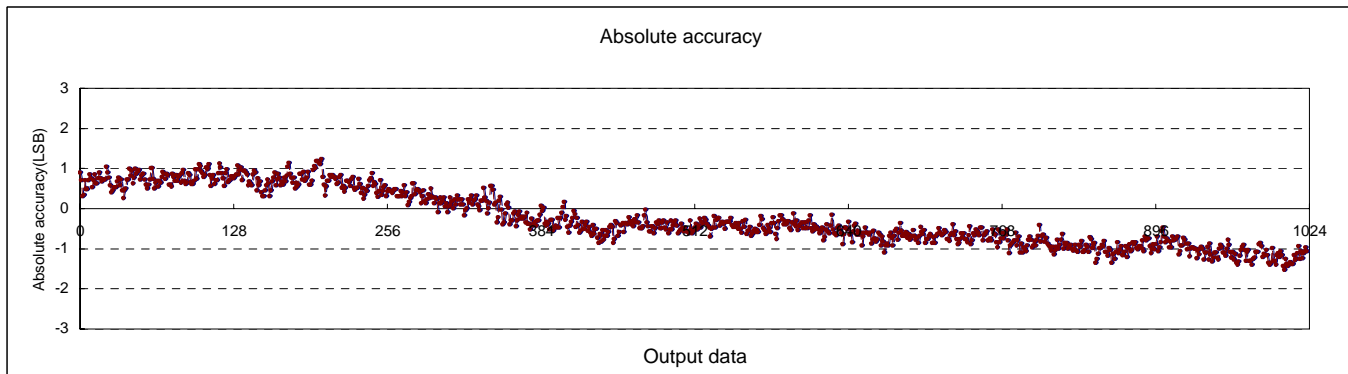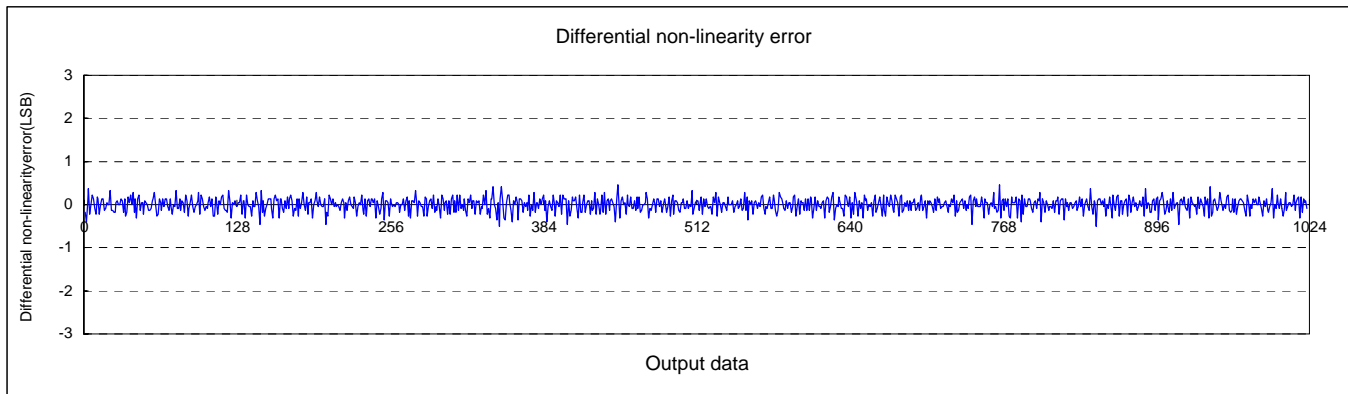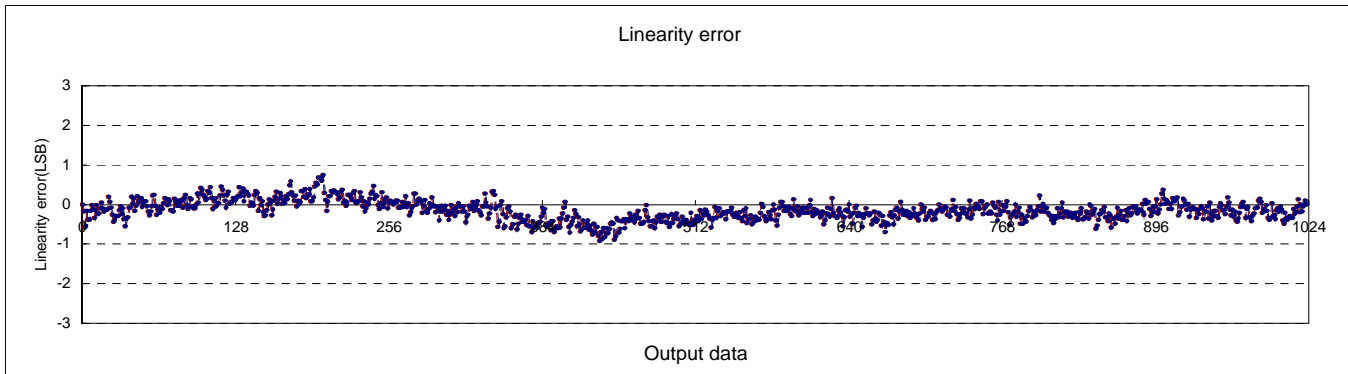

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.