

A/D accuracy 10bit

R8C/2A-2D Group




Topr = -40 degrees C

AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=3.379V

Xin=20MHz φAD=10MHz sample and hold=on Repeat mode

Absolute accuracy
-1.97LSB

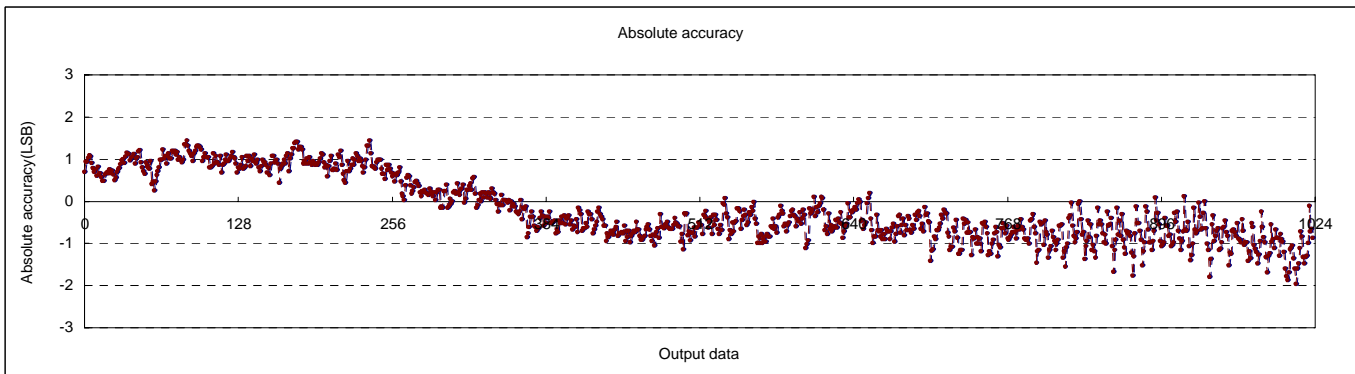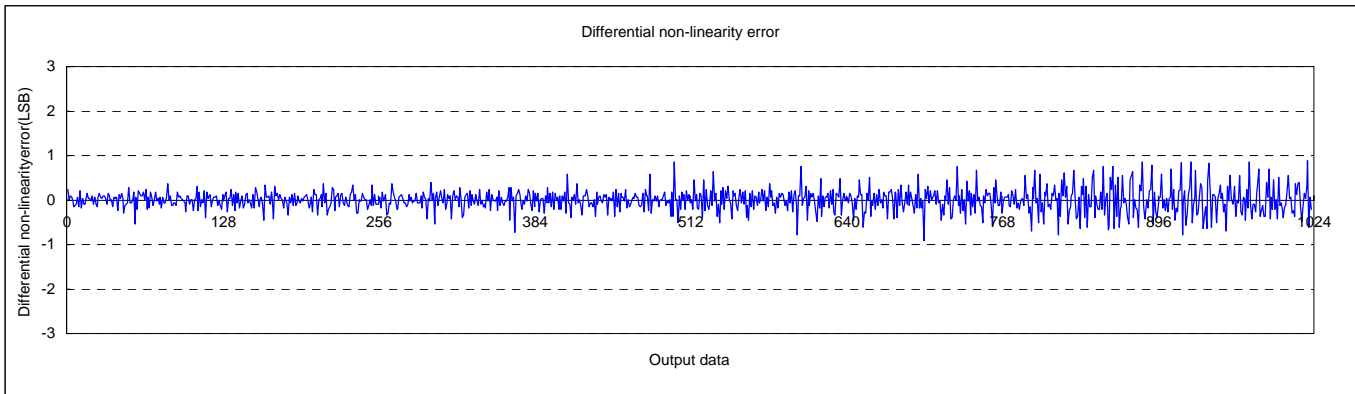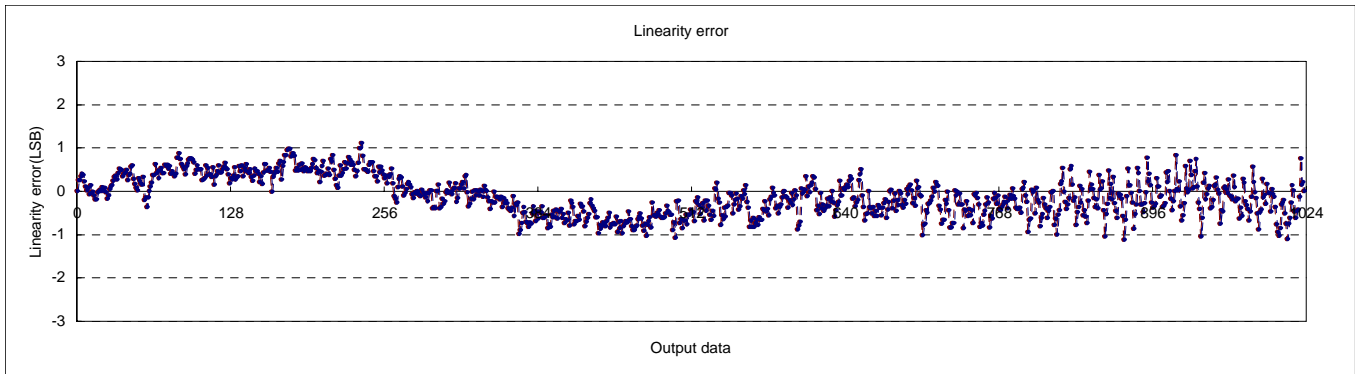

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.