



JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-HFQFP304-40x40-0.50	PRQP0304KB-C	P304GL-50-PMU	11.6

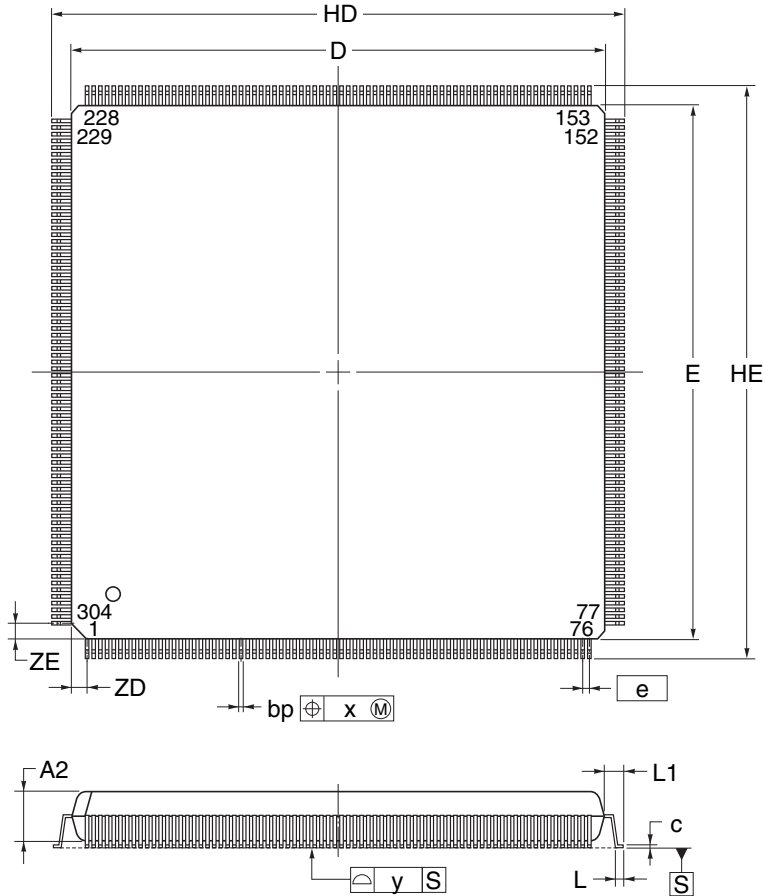

detail of lead end

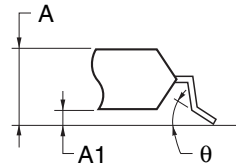

(UNIT:mm)

ITEM	DIMENSIONS
D	40.00±0.20
E	40.00±0.20
HD	42.60±0.20
HE	42.60±0.20
A	4.30 MAX.
A1	0.40±0.10
A2	3.70±0.10
bp	0.22 <sup>+0.05</sup> <sub>-0.04</sub>
c	0.145 <sup>+0.055</sup> <sub>-0.045</sub>
L	0.50±0.20
L1	1.30±0.20
θ	5°±5°
e	0.50
x	0.10
y	0.10
ZD	1.25
ZE	1.25

**NOTE**

Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.