


## 80-PIN PLASTIC QFP (14x20)

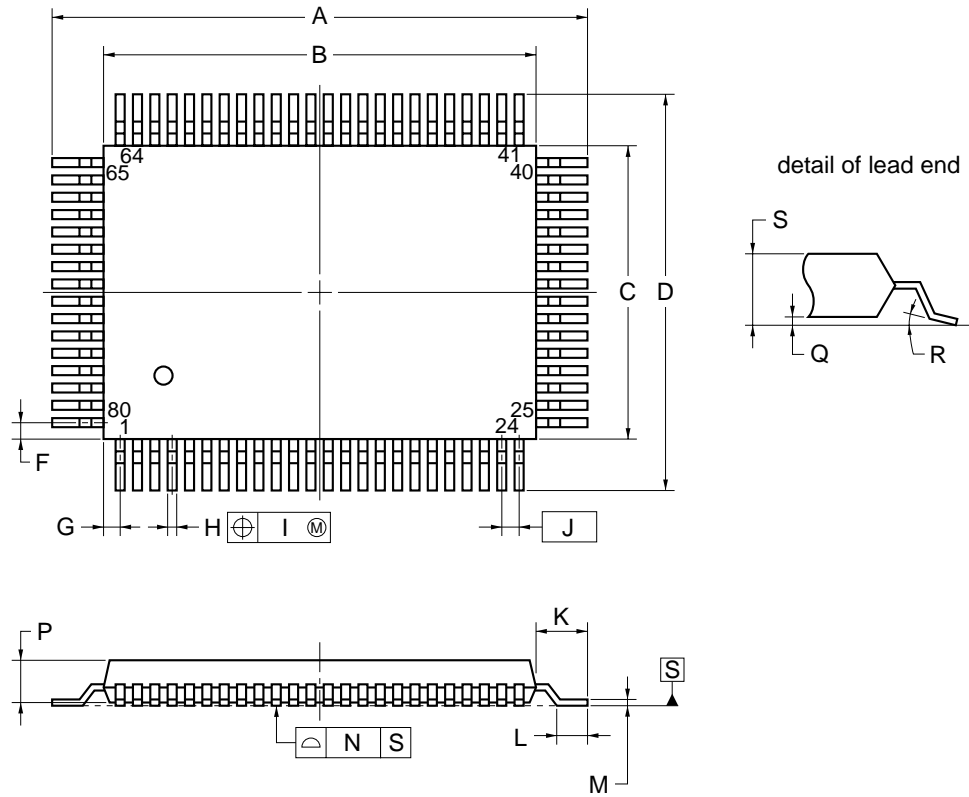

### NOTE

Each lead centerline is located within 0.15 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	24.0±0.4
B	20.0±0.2
C	14.0±0.2
D	18.0±0.4
F	1.0
G	0.8
H	0.35±0.10
I	0.15
J	0.8 (T.P.)
K	2.0±0.2
L	1.0±0.2
M	0.15 <sup>+0.10</sup> <sub>-0.05</sub>
N	0.15
P	2.6 <sup>+0.2</sup> <sub>-0.1</sub>
Q	0.1±0.1
R	5°±5°
S	3.0 MAX.

S80G-80-02-3