


# IOH vs VOH

(P0\_0-P0\_7, P3\_1, P3\_3-P3\_7, P4\_5, P5\_3, P5\_4)

Prepared on Sep. 07, 2007

R8C/26-27 Group  
Vcc = 3.0V

— 85 degree sC    — 25 degrees C  
— -40 degrees C

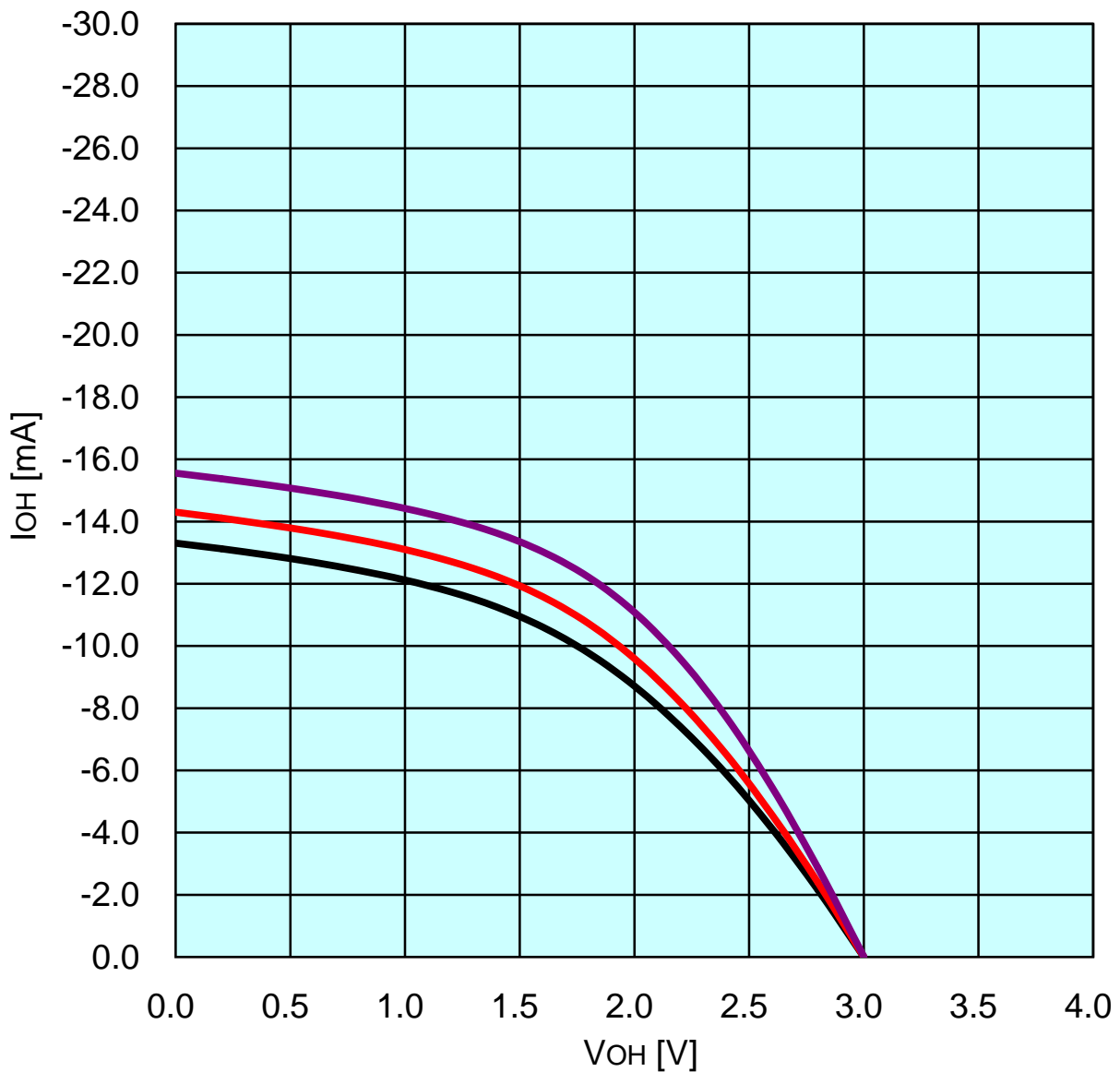

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.