

VOH vs VCC

(P2_0-P2_7 Drive Capacity=High)


Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)
R5F21258SDFP(Topr=-40 to 85degrees C)
Topr=25degrees C
IOH=-20mA, -5mA, -2mA

— IOH=-20mA

— IOH=-5mA

— IOH=-2mA

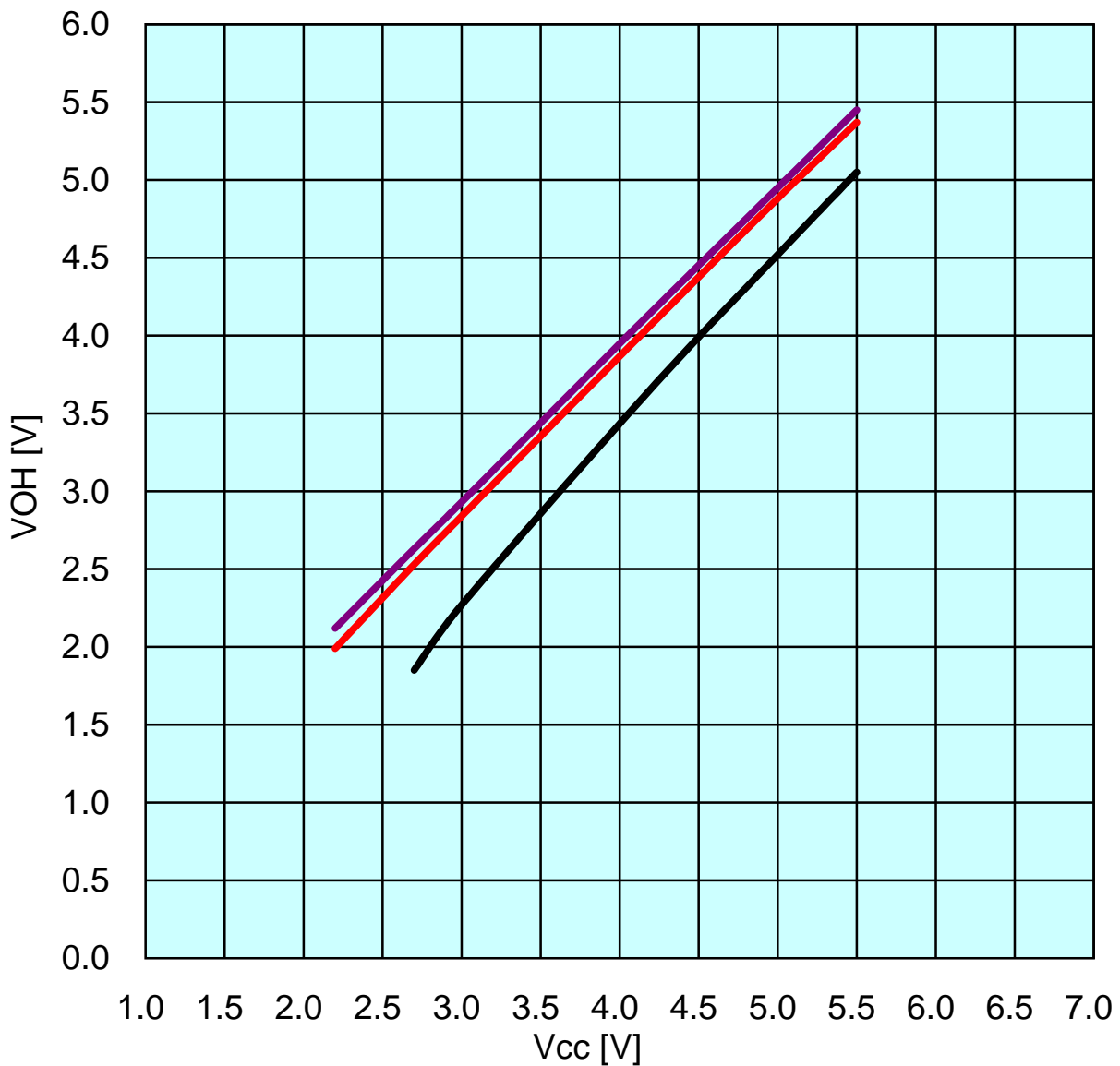

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.