


Package Name	JEITA Package Code	RENESAS Code	Previous Code	MASS[Typ.]
HWSON-6	P-HWSON6-3x3-0.80	PWSN0006ZA-A	—	0.022 g

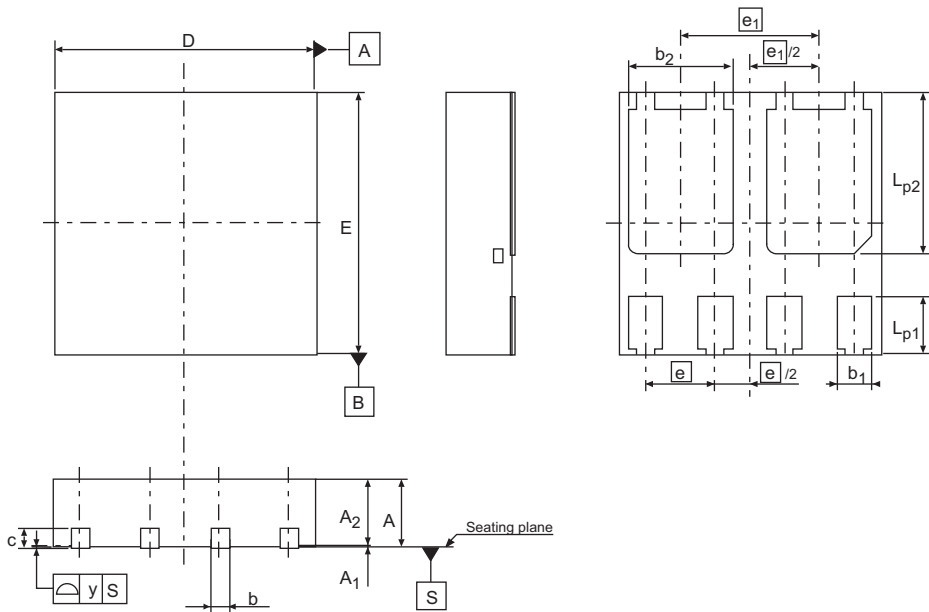

Reference Symbol	Dimension in Millimeters		
	Min	Nom	Max
A	0.70	—	0.80
A ₁	0	—	0.05
A ₂	0.70	—	0.75
b	—	0.20	—
b ₁	0.35	0.40	0.45
b ₂	1.10	1.15	1.20
c	—	0.20	—
D	2.90	3.00	3.10
E	2.90	3.00	3.10
e	—	0.80	—
e_1	—	1.60	—
L _{p1}	0.55	—	0.75
L _{p2}	1.75	—	1.95
y	—	—	0.05