


## 44-PIN PLASTIC QFP (STRAIGHT) (10x10)

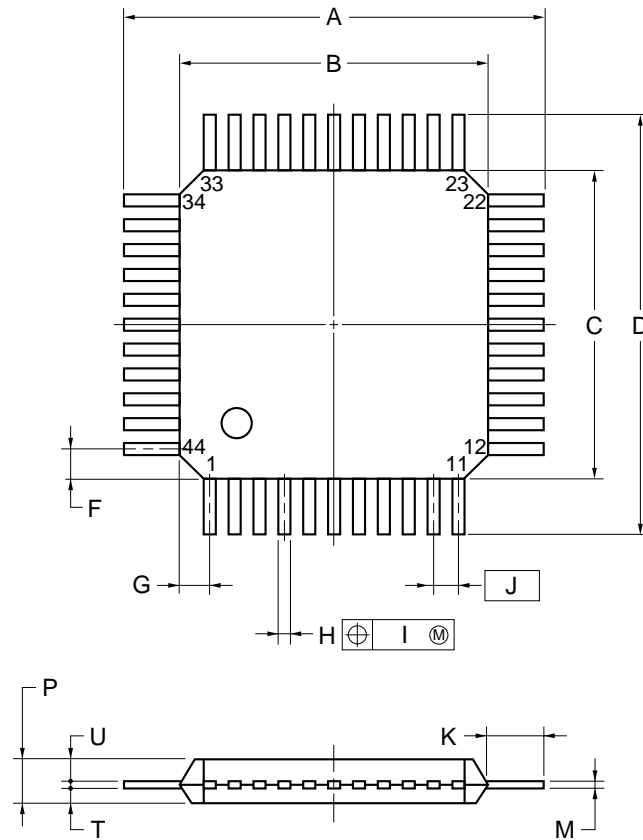

### NOTE

Each lead centerline is located within 0.15 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	13.8±0.4
B	10.0±0.2
C	10.0±0.2
D	13.8±0.4
F	1.0
G	1.0
H	0.35 <sup>+0.20</sup> <sub>-0.10</sub>
I	0.15
J	0.8 (T.P.)
K	1.9±0.2
M	0.15 <sup>+0.10</sup> <sub>-0.05</sub>
P	1.45±0.1
T	0.4
U	0.9

P44G-80-23-3