

# A-D accuracy 10bit

Type: R5F21258SNFP(Topr=-20 to 85degrees C)

R5F21258SDFP(Topr=-40 to 85degrees C)

Topr=25 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=5.120V

Xin=20MHz  $\phi_{AD}$ =10MHz sample and hold=on Repeat mode

Absolute accuracy  
-1.81LSB

Prepared on Oct. 20, 2006

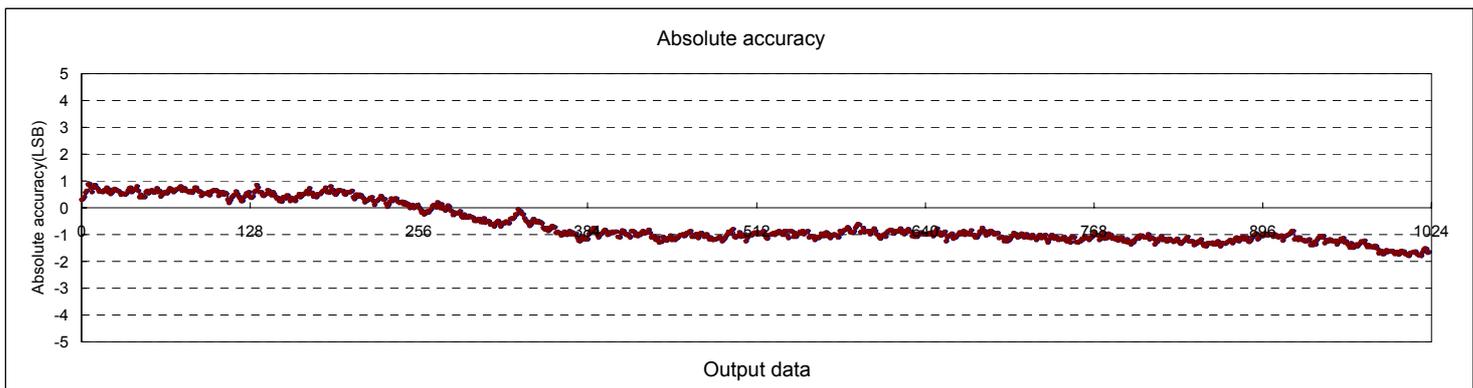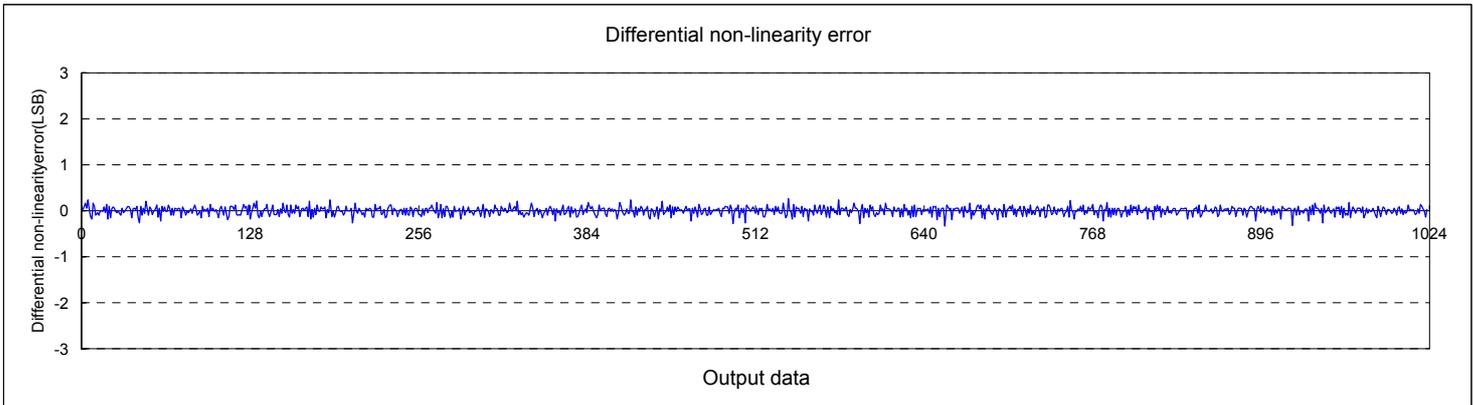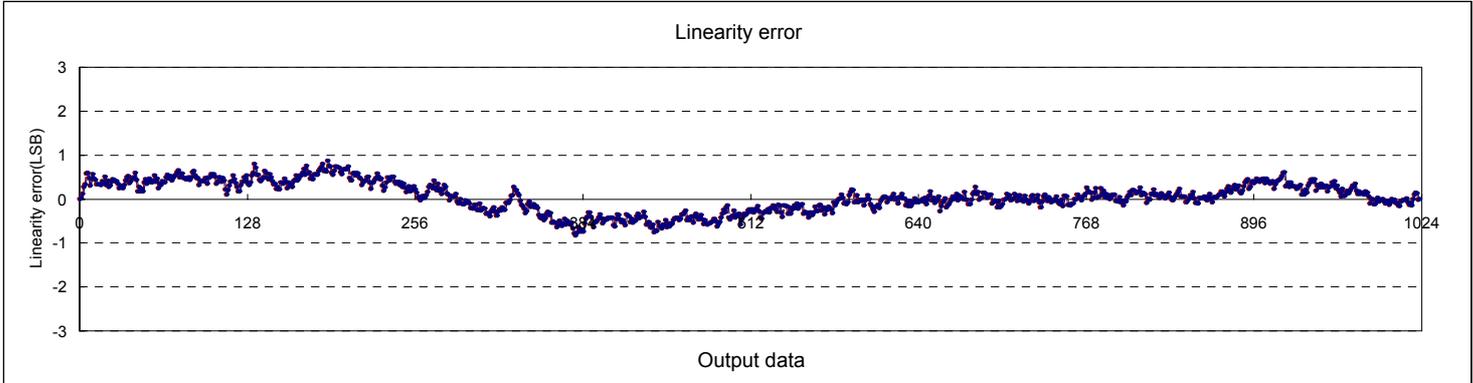

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.