

IOH vs VOH

(P0_0-P0_7,P1_0-P1_7,P3_0,P3_1,
P3_3-P3_5,P3_7,P4_2-P4_5,P6_0-P6_7)

Prepared on Oct. 20, 2006


R5F21258SNFP(Topr=-20 to 85degrees C)

R5F21258SDFP(Topr=-40 to 85degrees C)

Topr=25degrees Celsius

Vcc=5V, 3V, 2.2V

— Vcc=5V — Vcc=3V — Vcc=2.2V

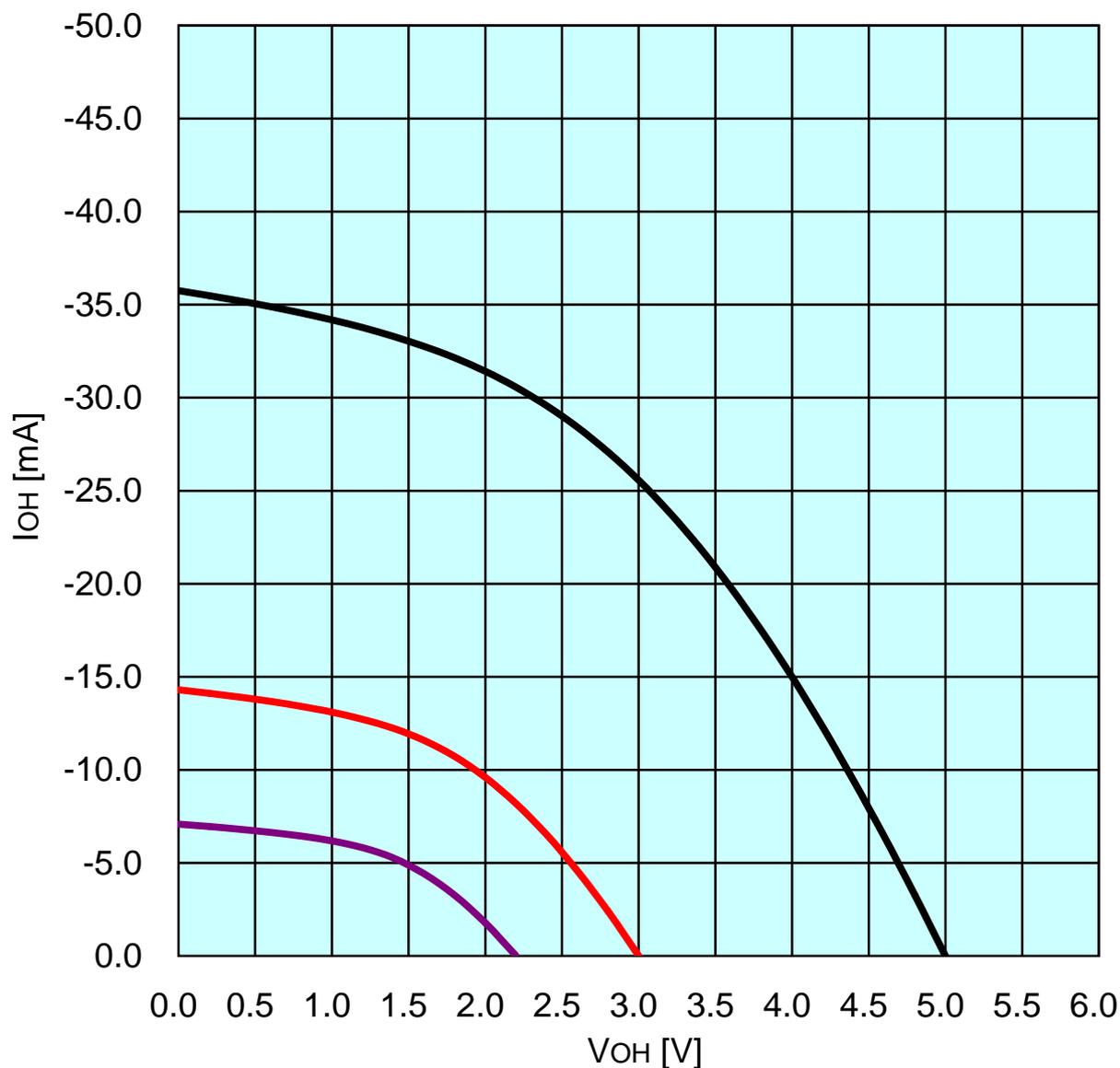

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.