

# VOH VS VCC

(P0\_0-P0\_7,P1\_0-P1\_7,P3\_0,P3\_1,  
P3\_3-P3\_5,P3\_7,P4\_2-P4\_5,P6\_0-P6\_7)

Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)

R5F21258SDFP(Topr=-40 to 85degrees C)


Topr=25degrees C

IOH=-5mA, -1mA, -200uA

— IOH=-5mA

— IOH=-1mA

— IOH=-200uA

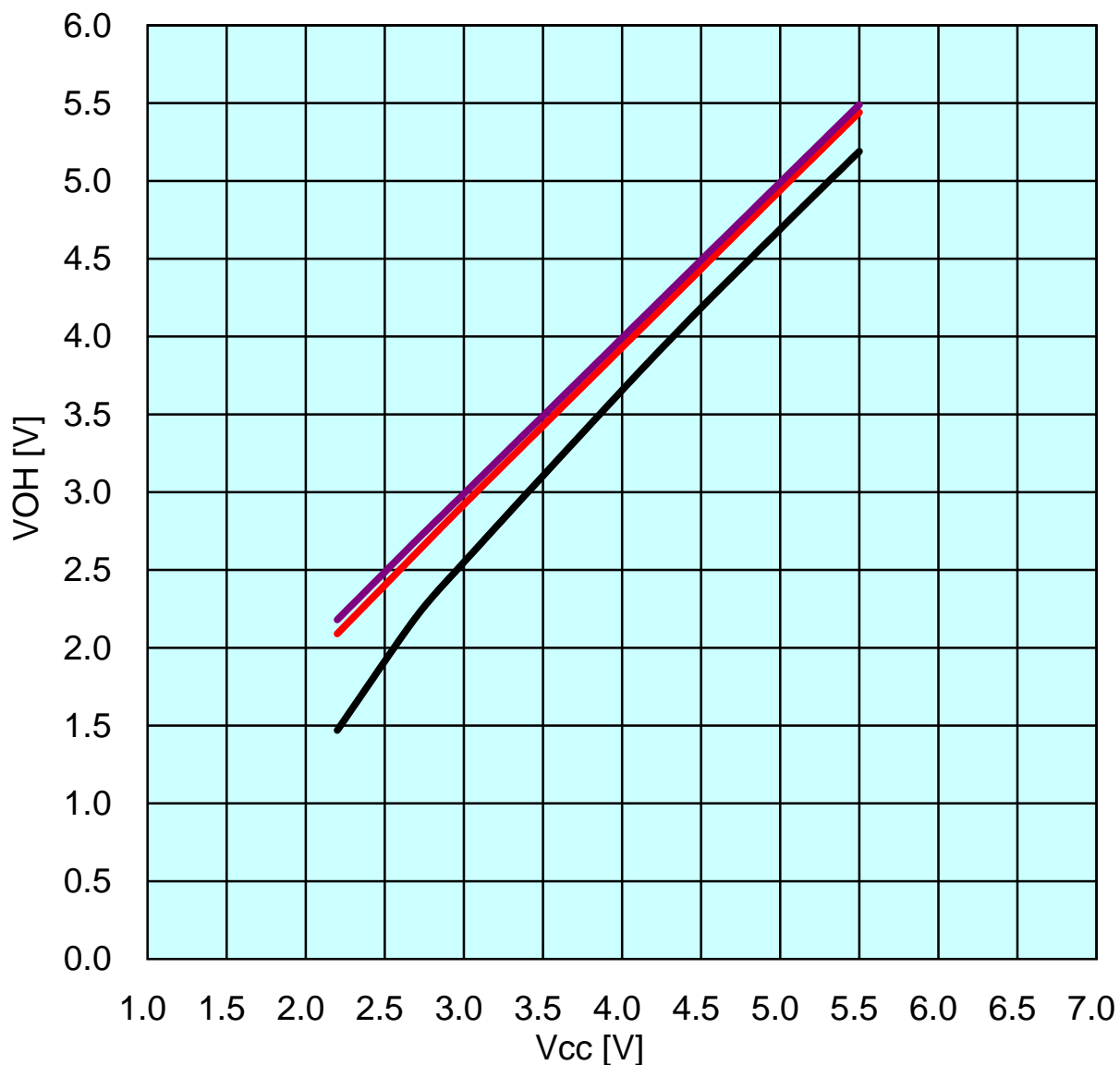

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.