

# A-D accuracy 10bit

Type: R5F21248SNFP (Topr=-20 to 85degrees C)

R5F21248SDFP (Topr=-40 to 85degrees C)

Topr=-40 degrees C




AVcc-Vss: 0.1uF Vref-Vss:0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=2.252V

Xin=10MHz  $\phi_{AD}$ =5MHz sample and hold=on Repeat mode Repeat mode

Absolute accuracy  
-1.60LSB

Prepared on Oct. 20, 2006

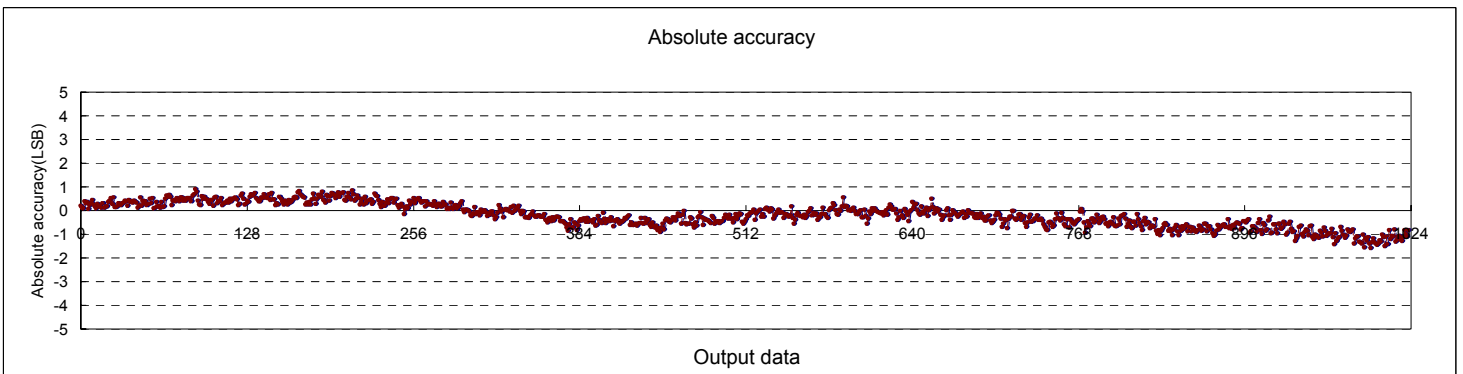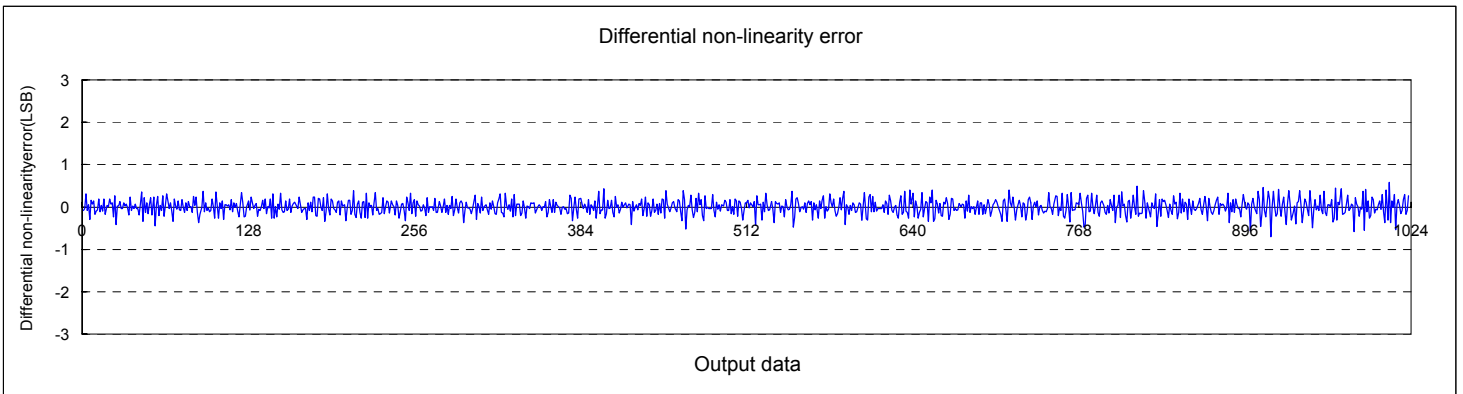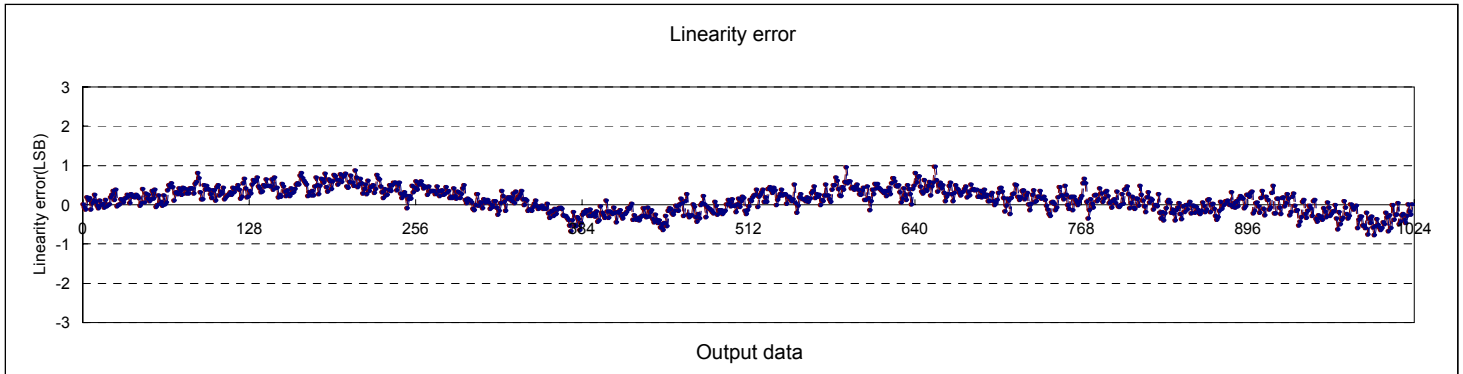

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.