

I_{cc} vs Topr


(High-speed on-chip oscillator mode on fOCO)

Prepared on Oct. 20, 2006

R5F21248SNFP (Topr=-20 to 85degrees C)
R5F21248SDFP (Topr=-40 to 85degrees C)
V_{cc}=3V
XIN clock off
High-speed on-chip oscillator on fOCO on
Low-speed on-chip oscillator on = 125 kHz

— fOCO=10MHz no division

— fOCO=10MHz divide by 8

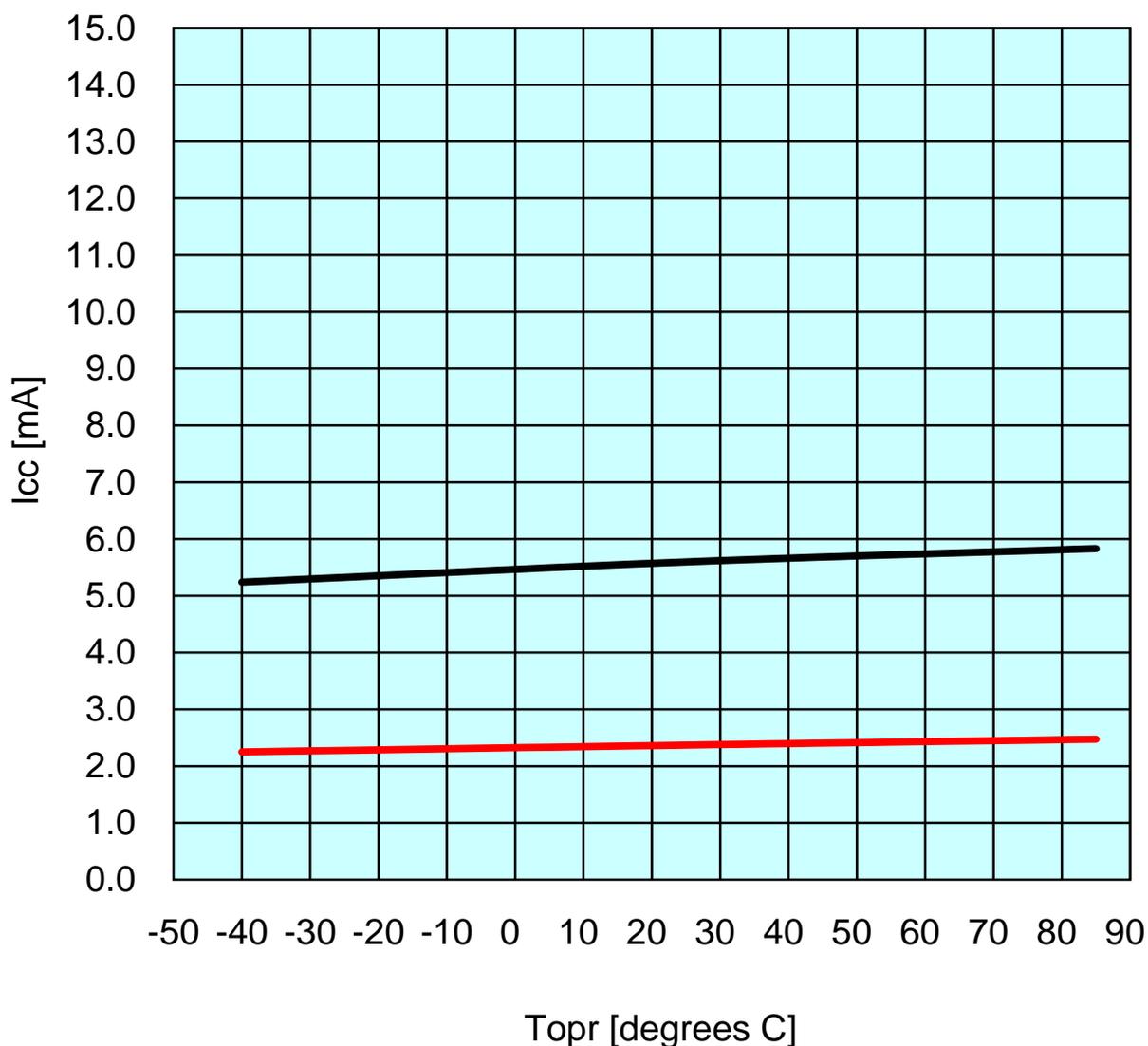

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.