


I_{OH} vs V_{OH} **(P1_0-P1_7 Drive Capacity=High)**

Prepared on Sep. 07, 2007

R8C/28-29 Group
V_{CC} = 3.0V

— 85 degrees C — 25 degrees C
— -40 degrees C

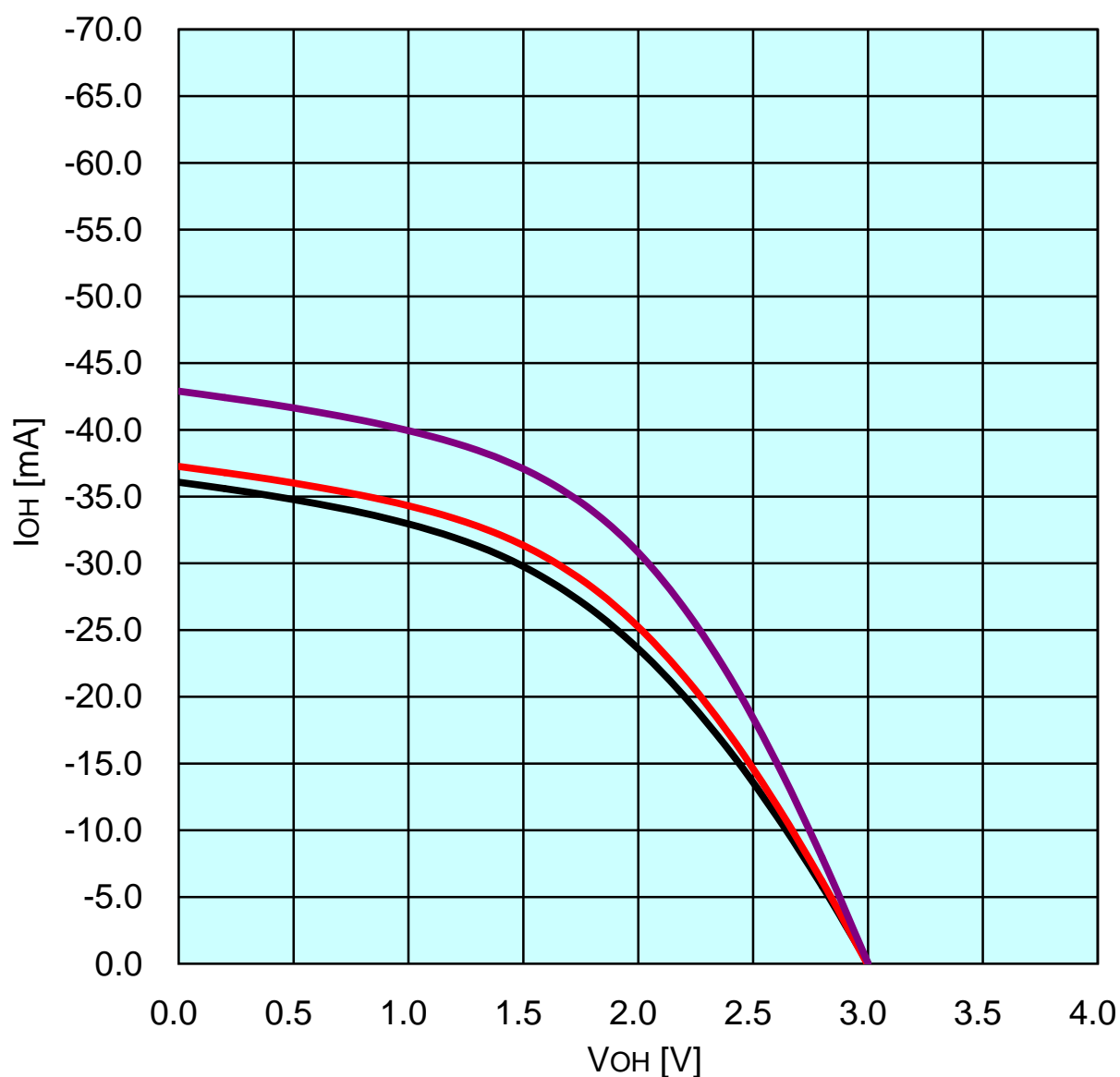

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.