


### M30620FCMFP A-D Accuracy

Condition : AVcc=Vcc=Vref=3.072V,f(Xin)=fAD=5MHz,8bit, AN0 without sample and hold function, Topr=25 degrees C

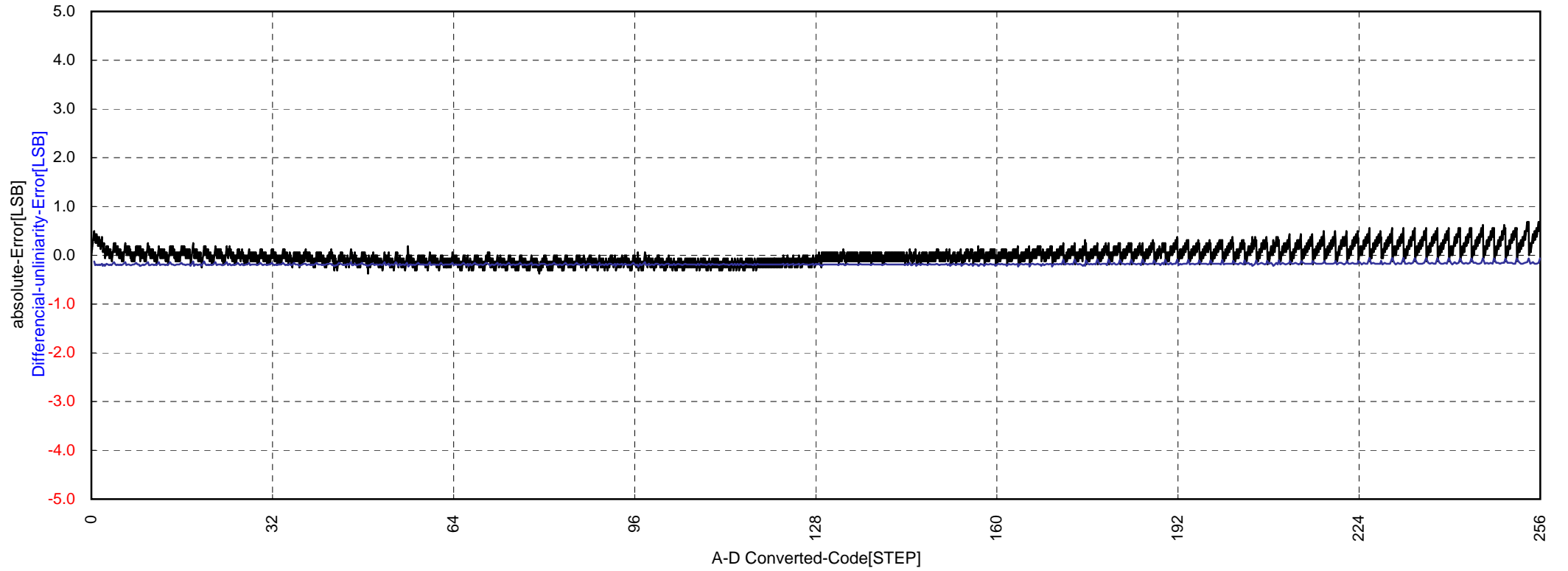

Caution! This Data is not guaranteed Value.