


M30624MGAFP A-D Accuracy  
Condition : AVcc=Vcc=Vref=5.12V,f(Xin)=fAD=10MHz,10bit, AN0 with sample and hold function, Topr=25 degrees C

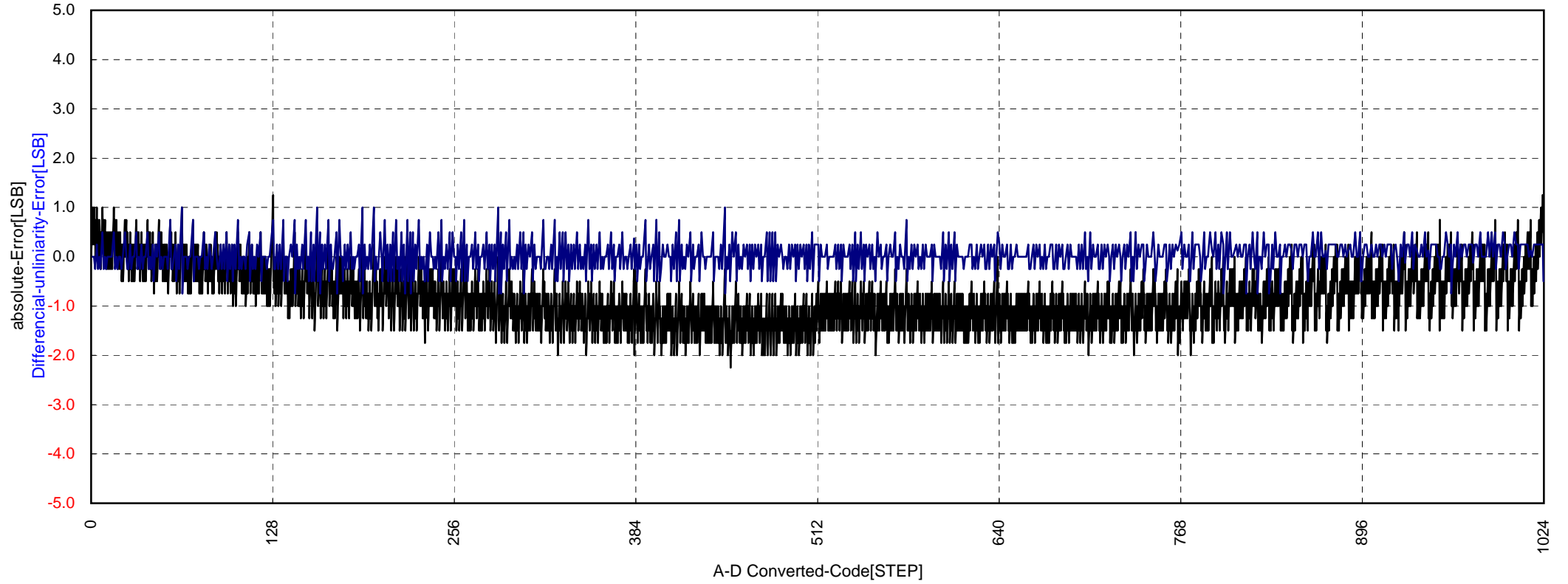

Caution! This Data is not guaranteed Value.