


### M30627FHP A-D Accuracy

Condition:AVcc=Vcc=Vref=3.072V,f(Xin)=fAD=10MHz,10bit,AN0 with sample and hold function,Topr=25 degrees C

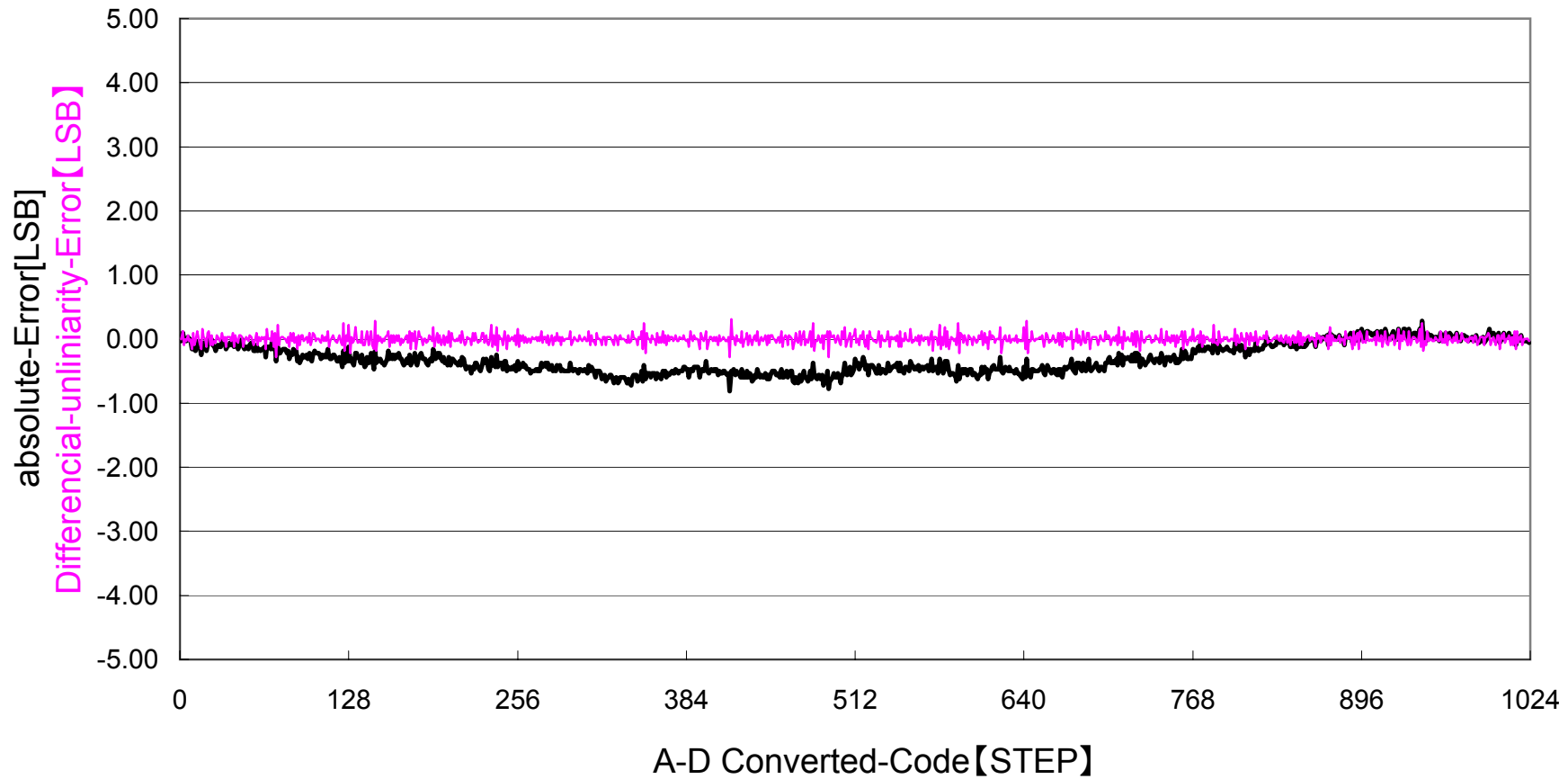

Caution!This Data is not guaranteed Value.