


M30627FHPFP D-A Accuracy

Condition : $A_{V_{cc}}=V_{cc}=V_{ref}=3.072V$, $f(X_{in})=7.0MHz$, $T_{opr}=25$ degrees C, 1LSB-Width = 12mV

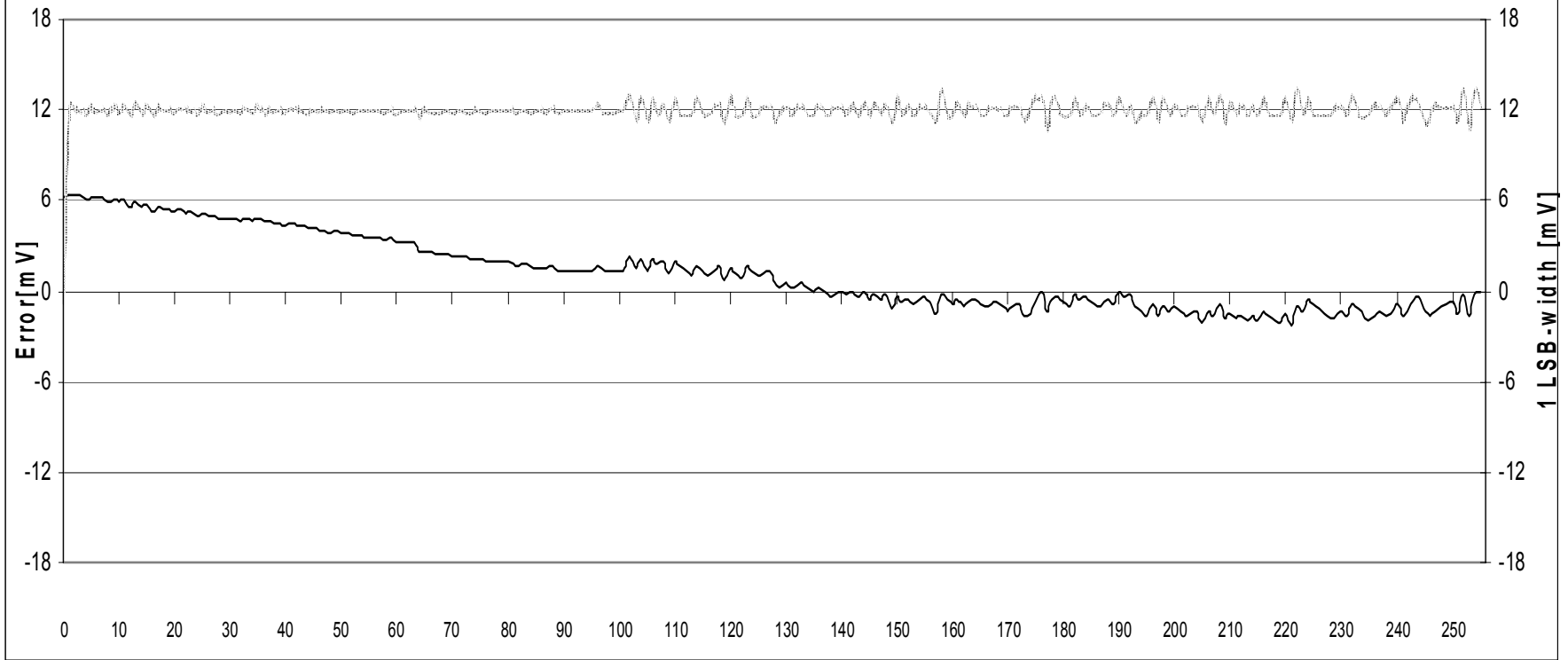

D-A input Code Value

Caution! This is not guaranteed Value