


M3062GF8NFP A-D AccuracyCondition : AVcc=Vcc=Vref=3.3V,f(Xin)=fAD=10.0MHz,10bit, AN0 with sample and hold function, Topr=25 degrees C

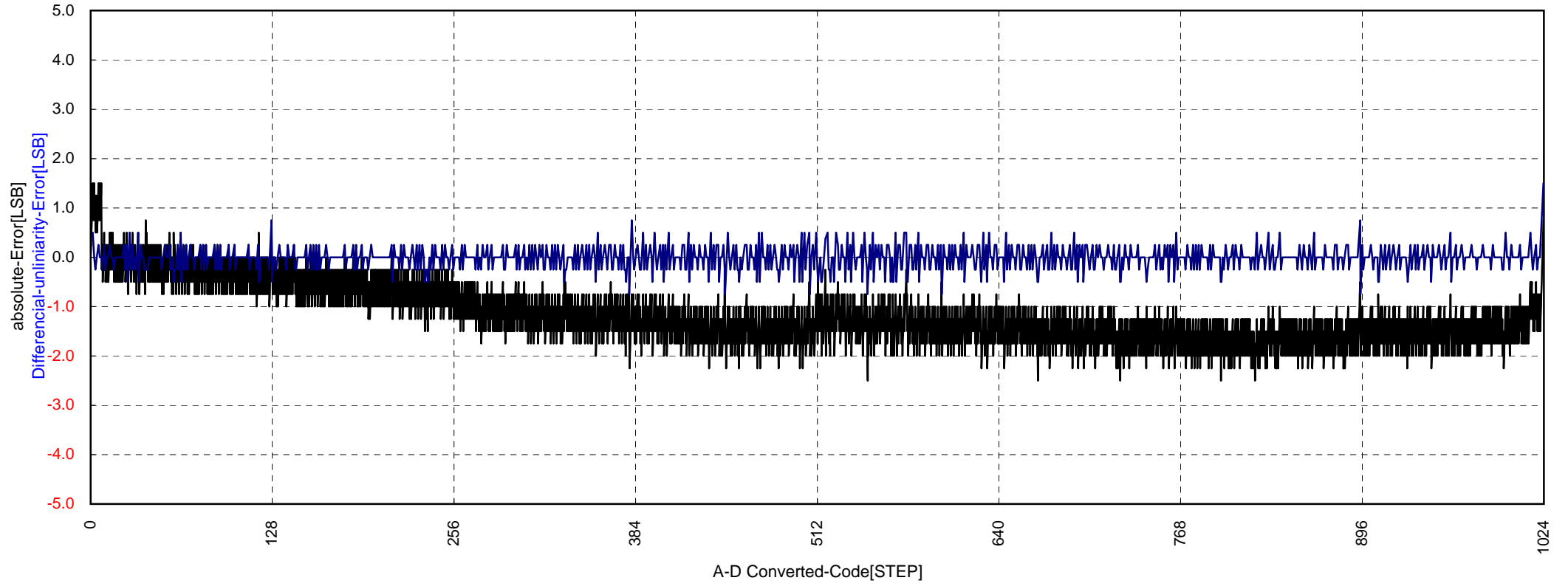

Caution! This Data is not guaranteed Value.