

A-D accuracy 10bit

Type: R5F21248SNFP (Topr=-20 to 85degrees C)

R5F21248SDFP (Topr=-40 to 85degrees C)

Topr=-40 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=3.379V

Xin=20MHz ϕ AD=10MHz sample and hold=on Repeat mode

Absolute accuracy
-1.97LSB

Prepared on Oct. 20, 2006

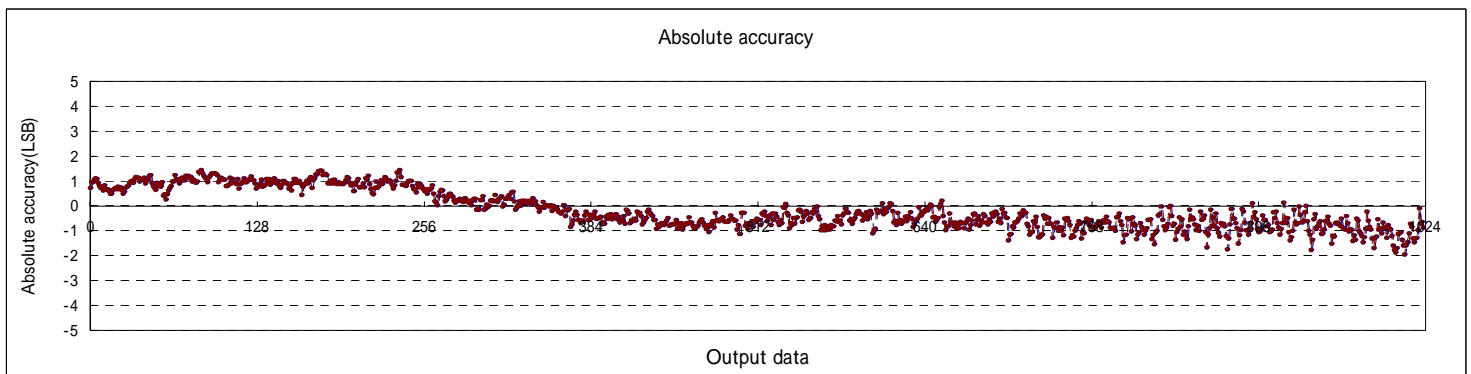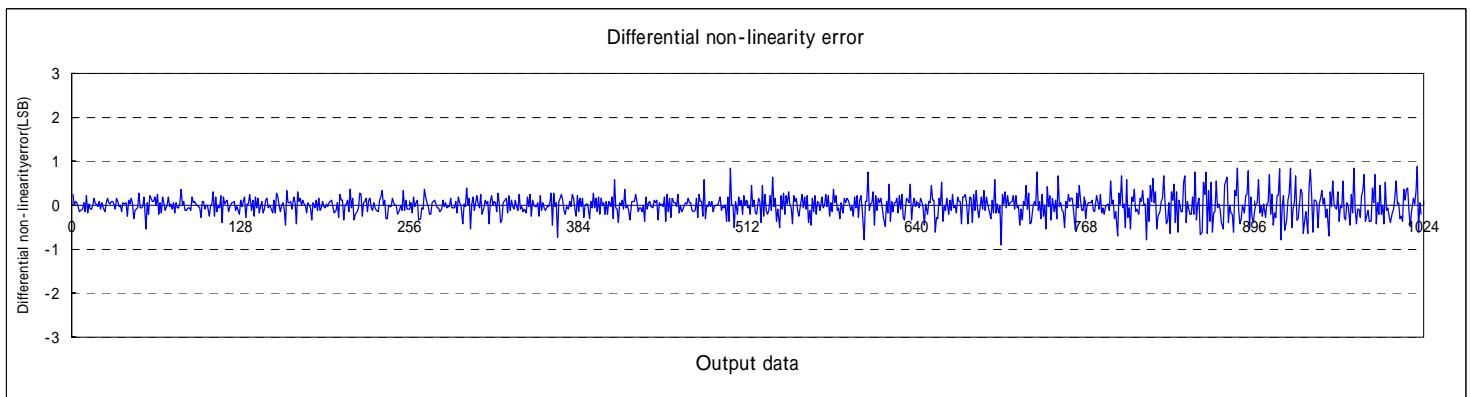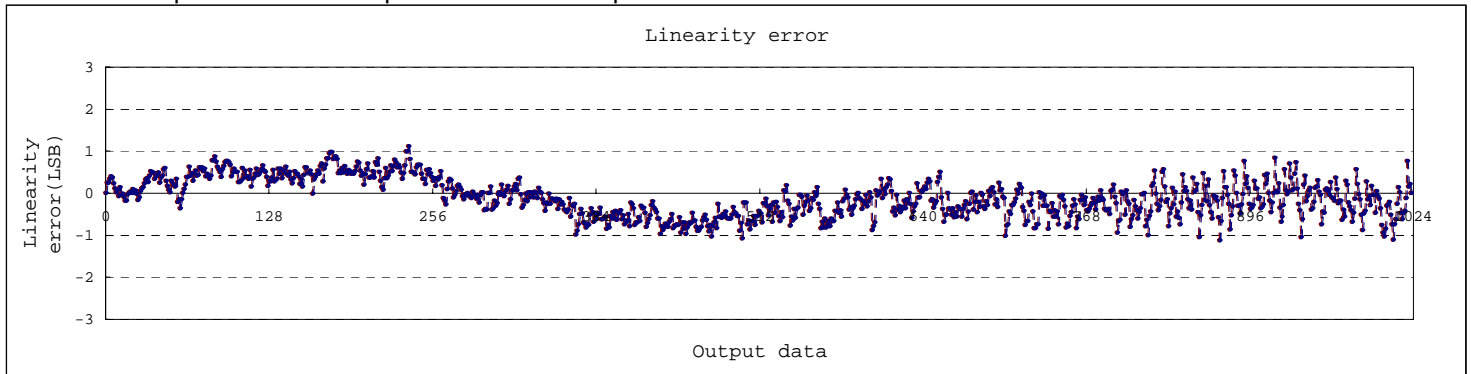

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.