

IOH vs VOH

(P0_0-P0_7,P1_0-P1_7,P3_0,P3_1,
P3_3-P3_5,P3_7,P4_2-P4_5,P6_0-P6_7)

Prepared on Oct. 20, 2006

R5F21248SNFP (Topr=-20 to 85degrees C)


R5F21248SDFP (Topr=-40 to 85degrees C)

Vcc=2.2V

— 85degreesC

— 25degreesC

— -40degreesC

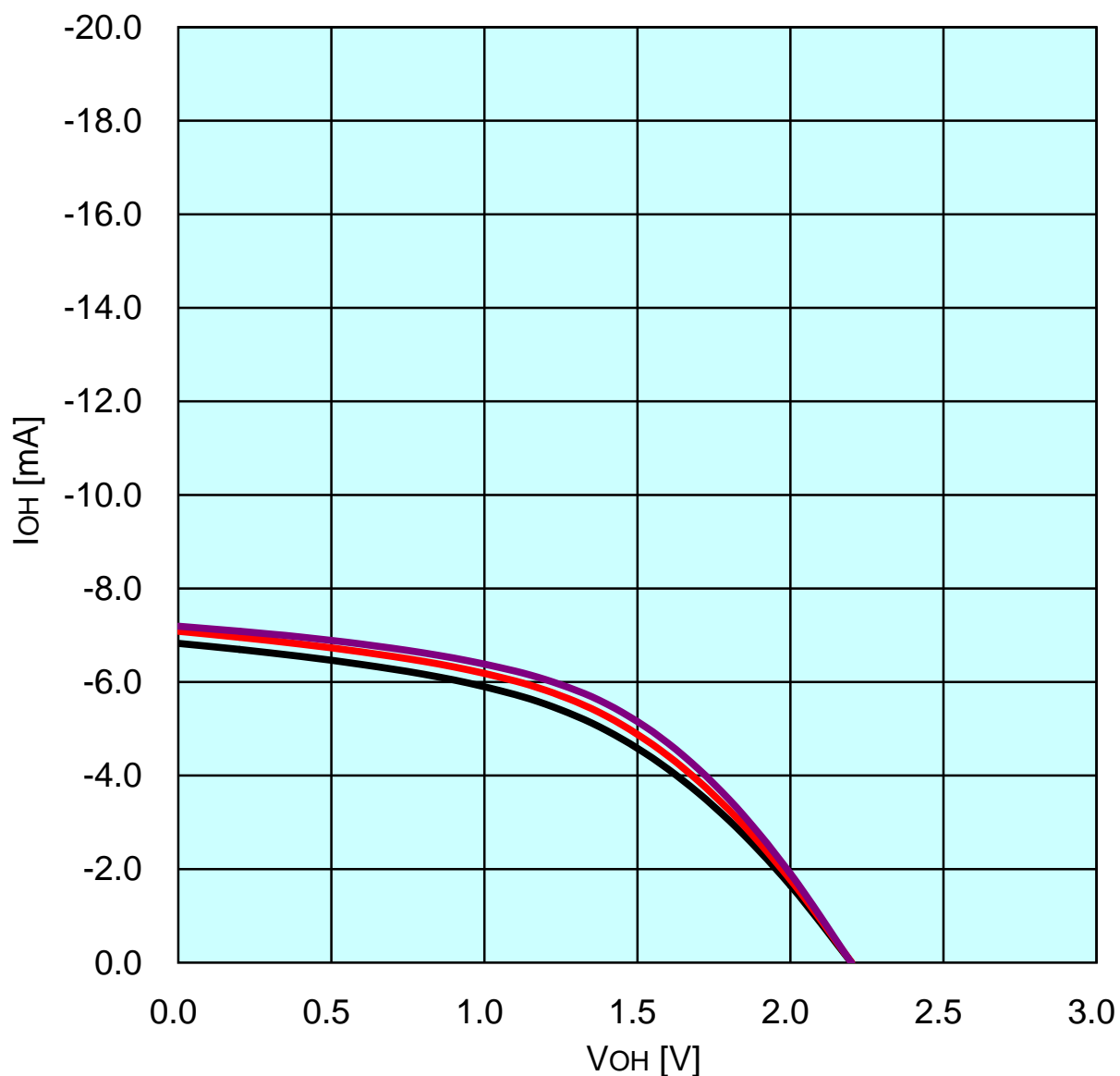

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.