


I_{OH} vs V_{OH} **(P2_0-P2_7 Drive Capacity=Low)**

Prepared on Jul. 29, 2007

R8C/2A-2D Group
V_{CC} = 3.0V

— 85 degrees C — 25 degrees C
— -40 degrees C

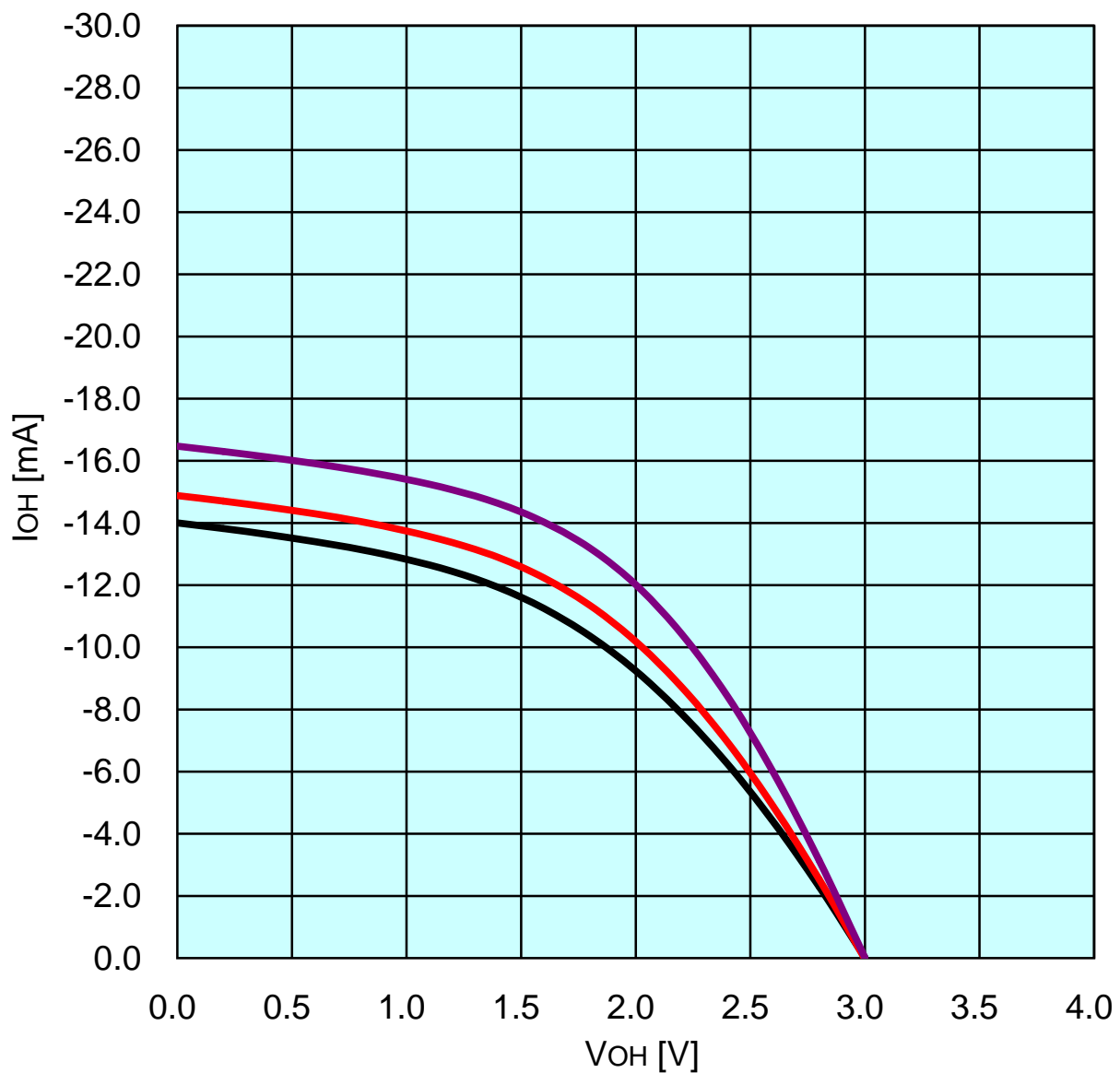

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.