

A-D accuracy 10bit

Type: R8C/2K Group

Topr=-40 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=3.379V

Xin=20MHz ϕ_{AD} =10MHz sample and hold=on Repeat mode

Absolute accuracy
-1.97LSB

Prepared on Feb. 21, 2008

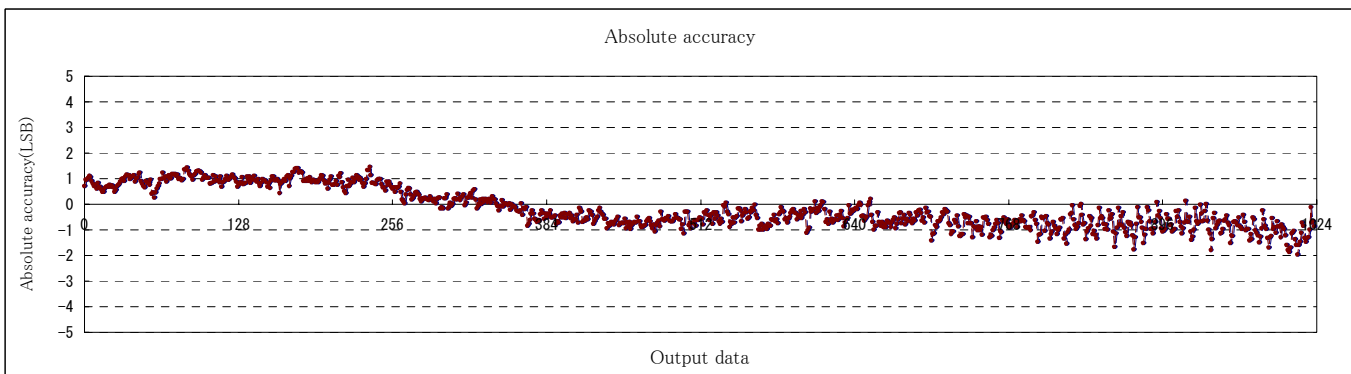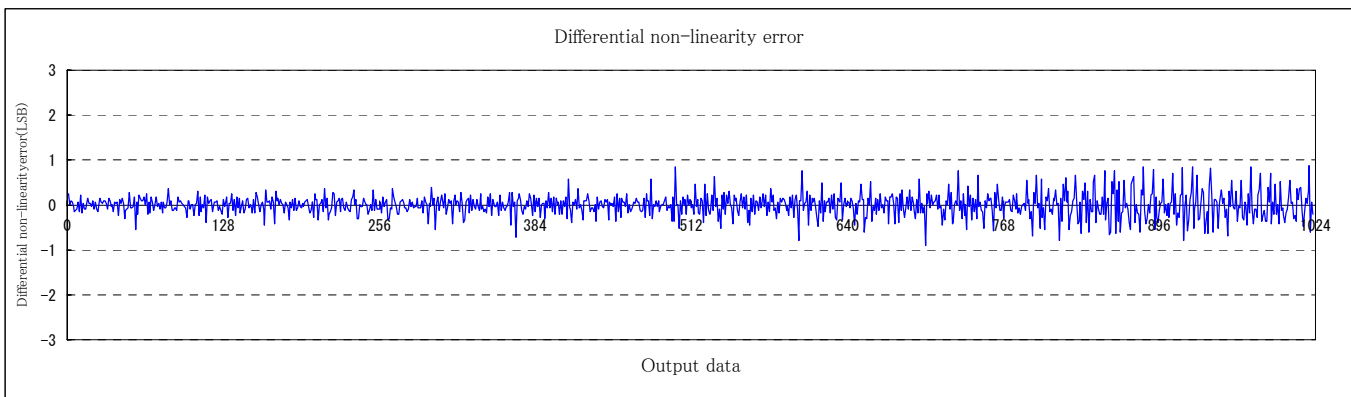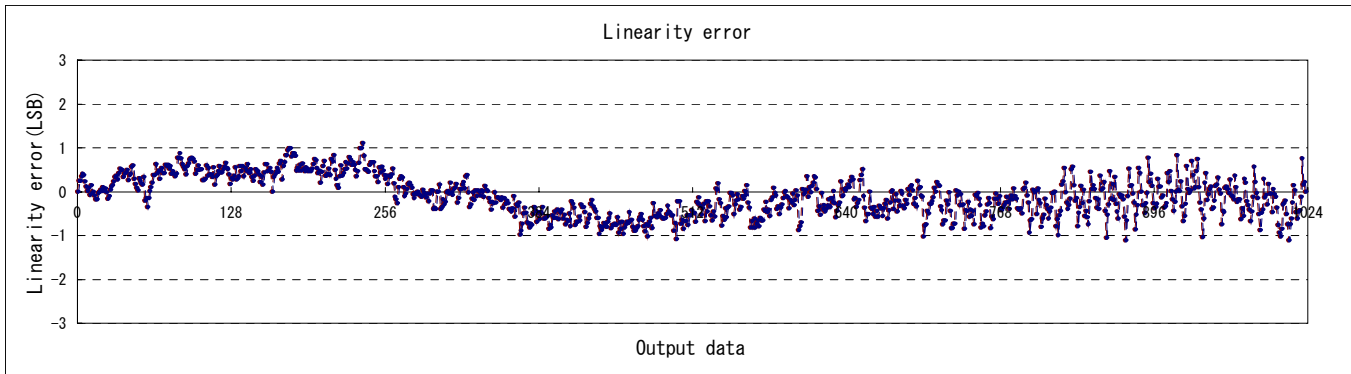

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.