


# V<sub>OH</sub> vs V<sub>CC</sub>

(P10-P12, P14-P17, P20-P24, P30-P37, P50-P55, P60-P67, P70-P72, P74-P76, P85-P87)

Prepared on : February 23, 2007

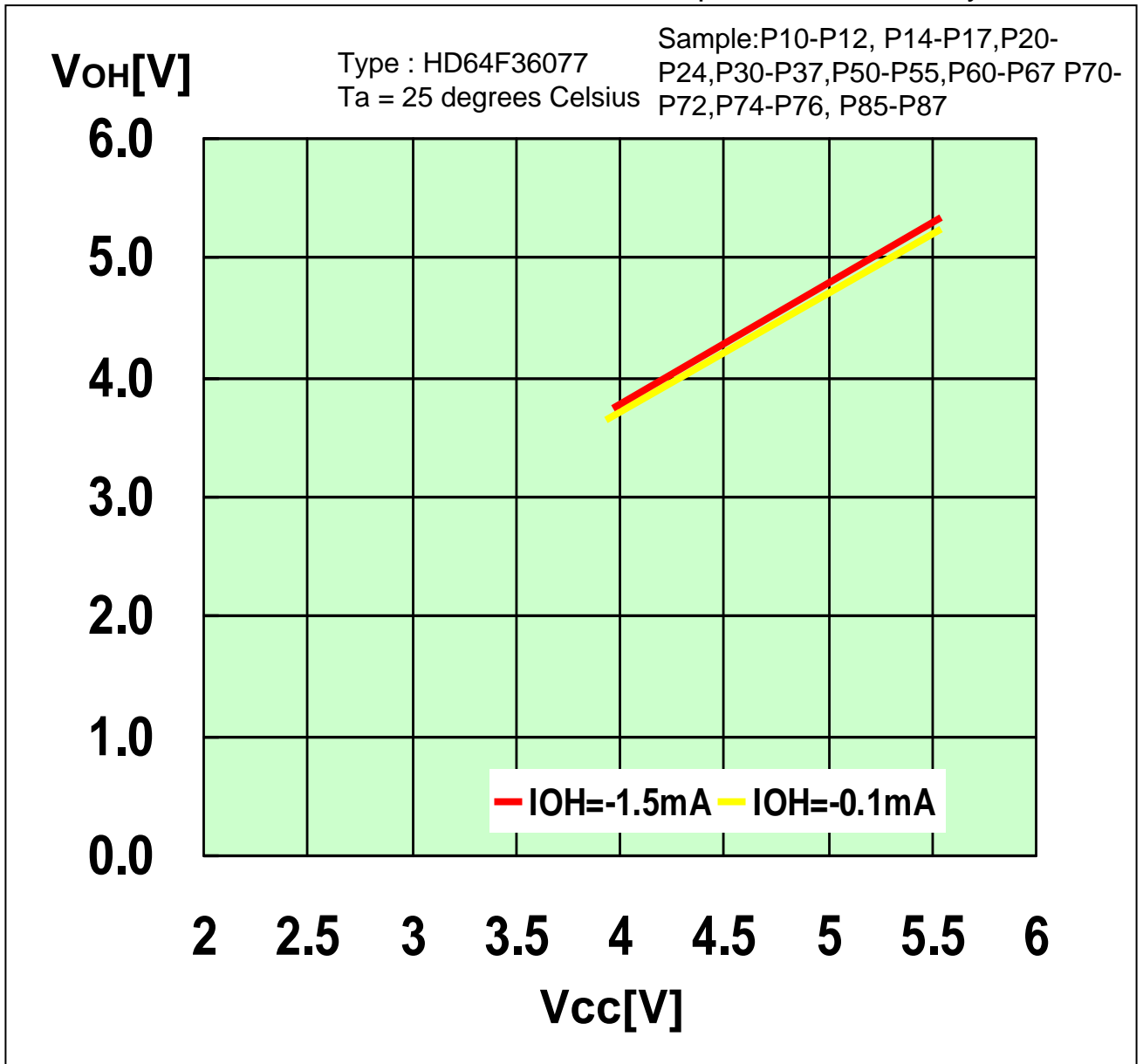

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.