


Icc vs Topr (High-speed clock mode)

Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)
R5F21258SDFP(Topr=-40 to 85degrees C)
Vcc=5V
XIN (square wave)
High-speed on-chip oscillator off
Low-speed on-chip oscillator on = 125 kHz

— XIN=20MHz no division
— XIN=20MHz divide by 8
— XIN=10MHz no division
— XIN=10MHz divide by 8

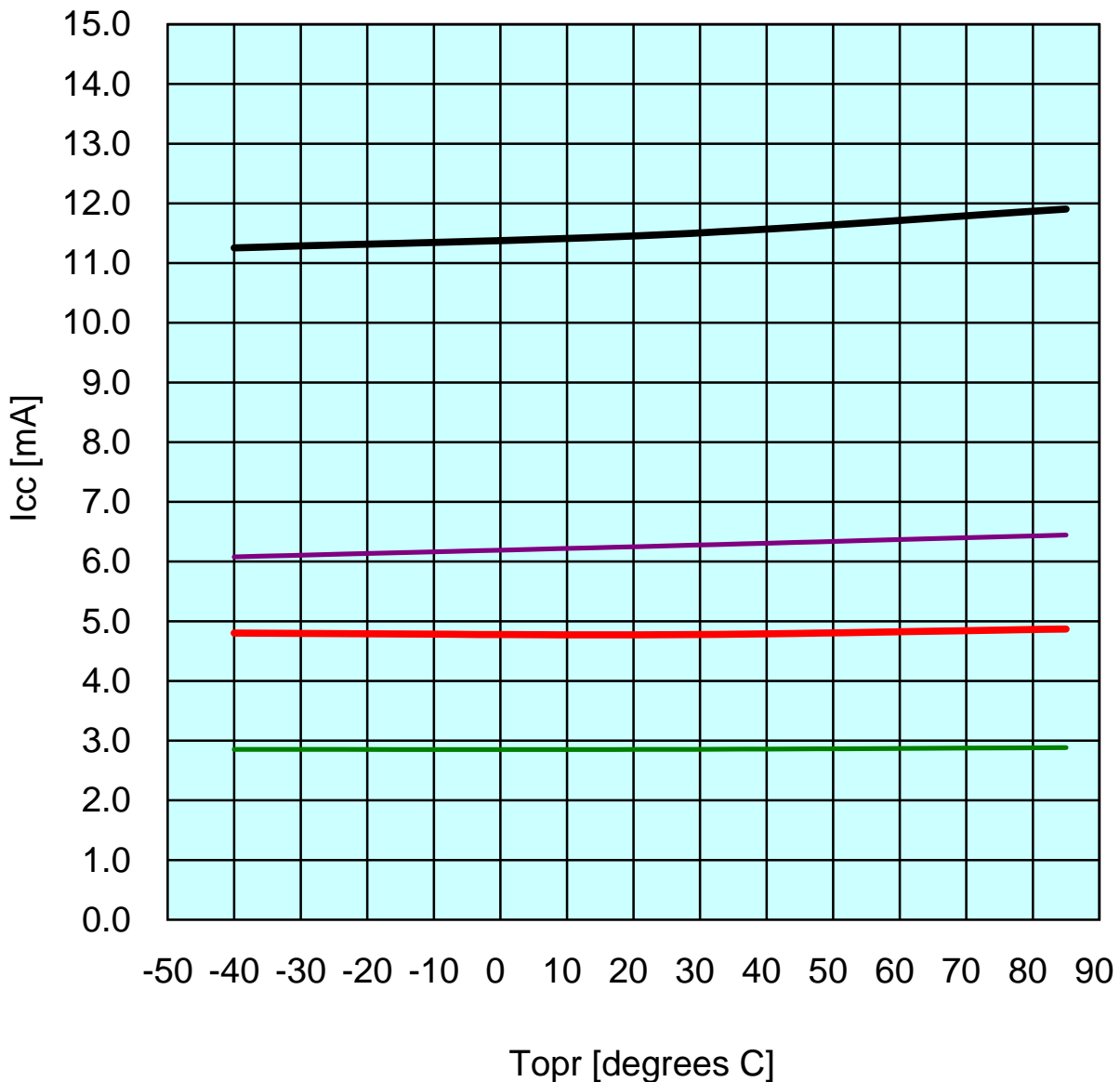

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.