

# A/D accuracy 10bit

R8C/26-27 Group

Topr = -40 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=5.120V

Xin=20MHz  $\phi_{AD}$ =10MHz sample and hold=on Repeat mode

Absolute accuracy  
-2.61LSB

Prepared on Sep. 07, 2007

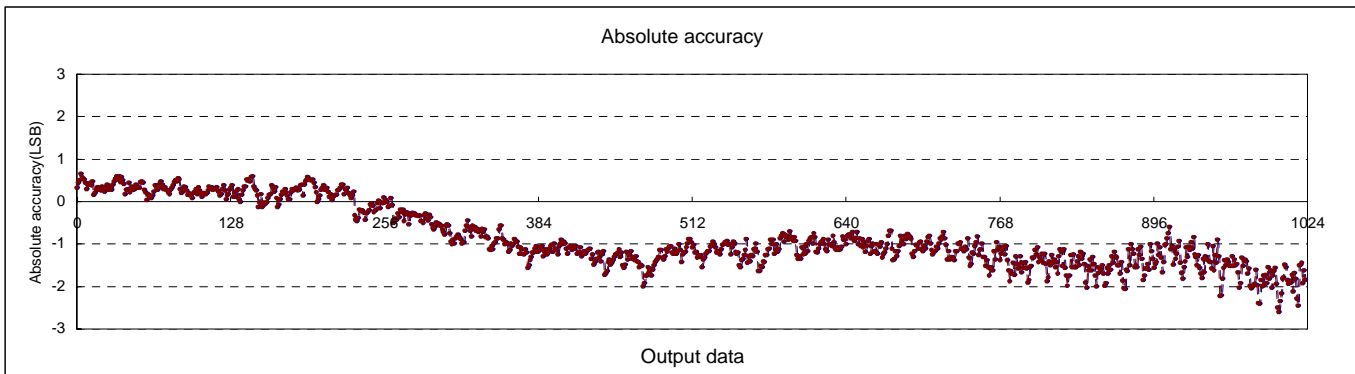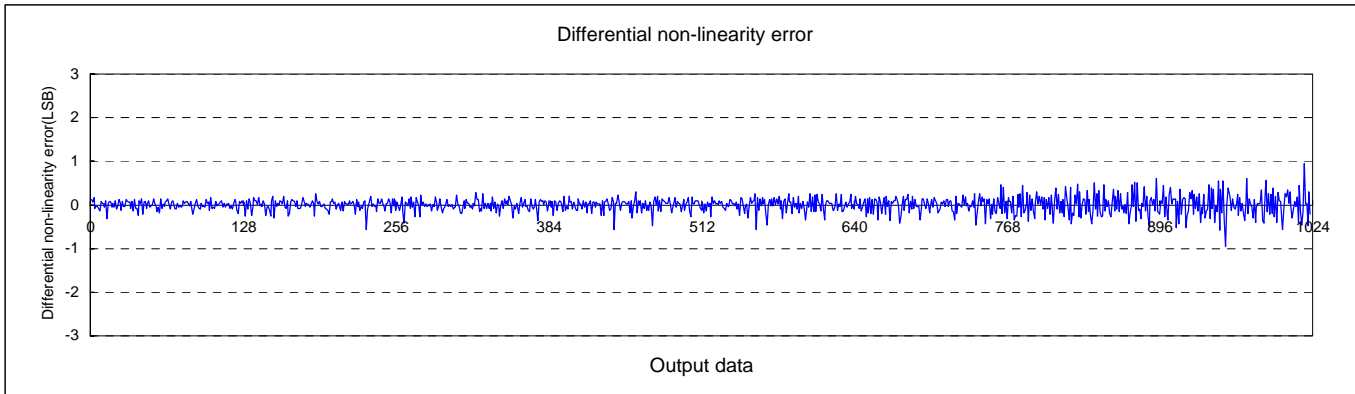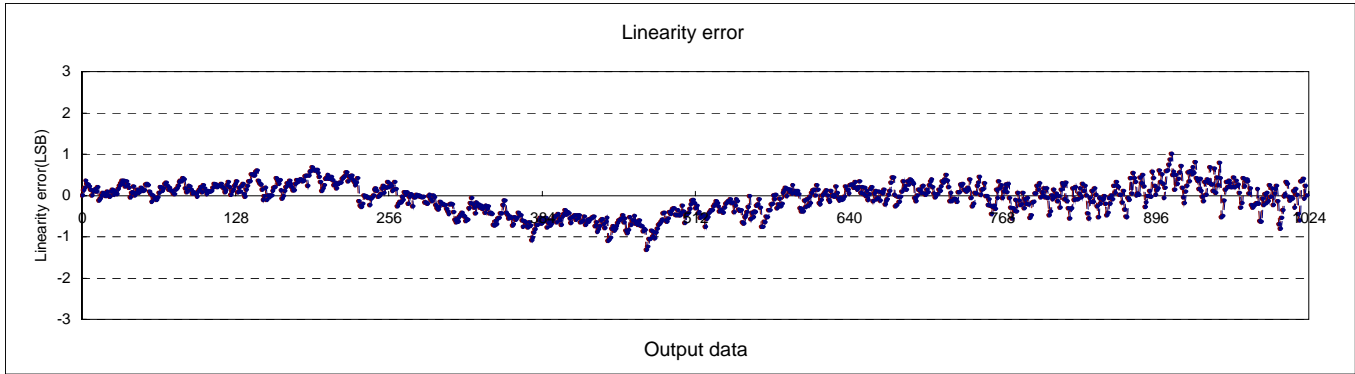

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.