

VOH vs Vcc

(P1_0-P1_7 Drive Capacity=High)

Prepared on Sep. 10, 2007

R8C/26-27 Group


Topr = 25 degrees C

IOH = -20mA, -5mA, -2mA

— IOH = -20mA

— IOH = -5mA

— IOH = -2mA

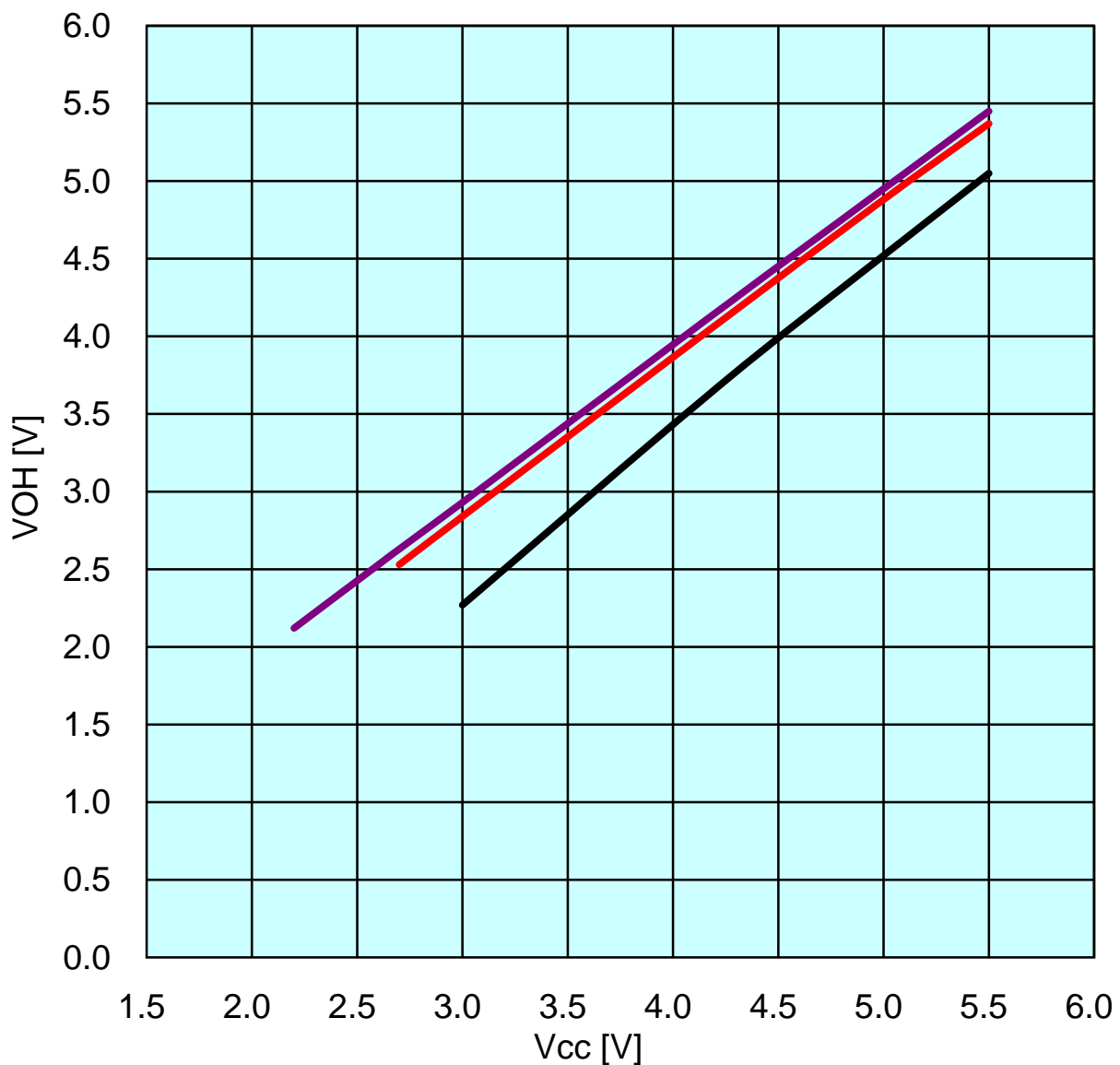

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.