


24-PIN PLASTIC ZIP (11.64 mm (475))

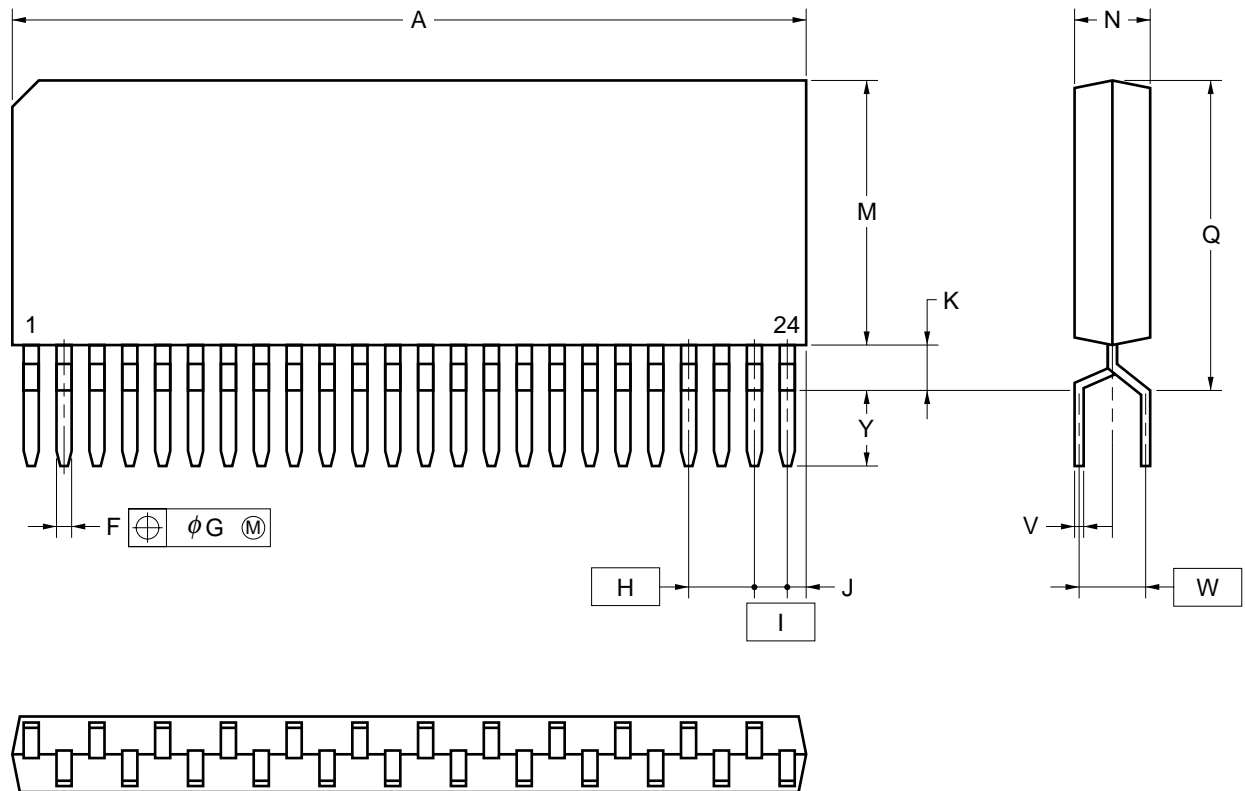

NOTE

Each lead centerline is located within 0.25 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	31.75 MAX.
F	0.50±0.1
G	φ 0.25
H	2.54
I	1.27
J	1.27 MAX.
K	1.0 MIN.
M	10.8 MAX.
N	2.8±0.2
Q	12.07 MAX.
V	0.25 ^{+0.10} _{-0.05}
W	2.54
Y	3.3±0.5

P24V-100-475A-1