


I_{cc} vs Topr

(High-speed on-chip oscillator mode on fOCO)

Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)
R5F21258SDFP(Topr=-40 to 85degrees C)
V_{cc}=5V
XIN clock off
High-speed on-chip oscillator on fOCO on
Low-speed on-chip oscillator on = 125 kHz

— fOCO=20MHz no division
— fOCO=20MHz divide by 8
— fOCO=10MHz no division
— fOCO=10MHz divide by 8

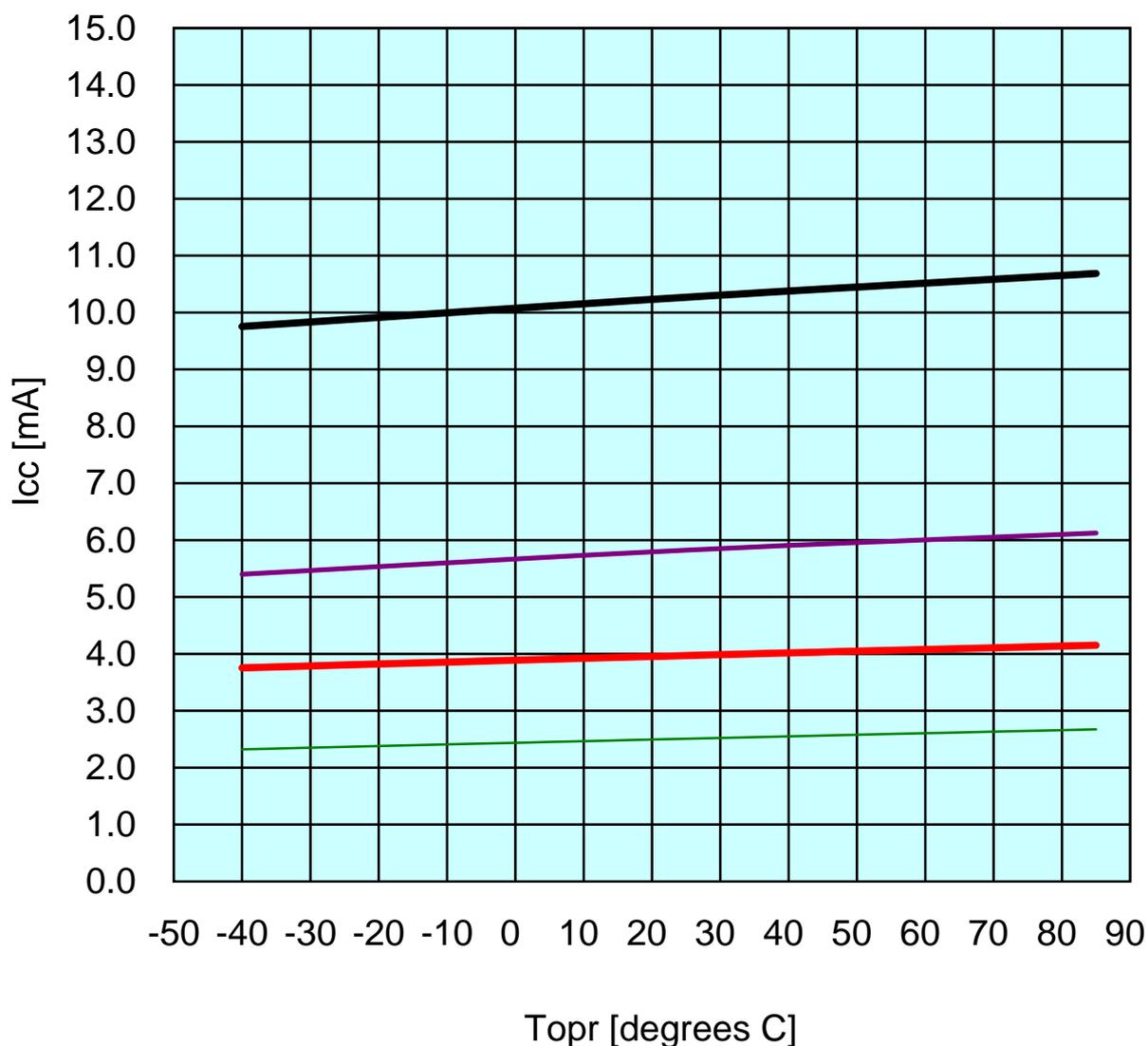

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.