

# VOH vs VCC


(P2\_0-P2\_7 Drive Capacity=Low)

Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)  
R5F21258SDFP(Topr=-40 to 85degrees C)  
Topr=25degrees C  
IOH= -5mA, -1mA

— IOH=-5mA

— IOH=-1mA

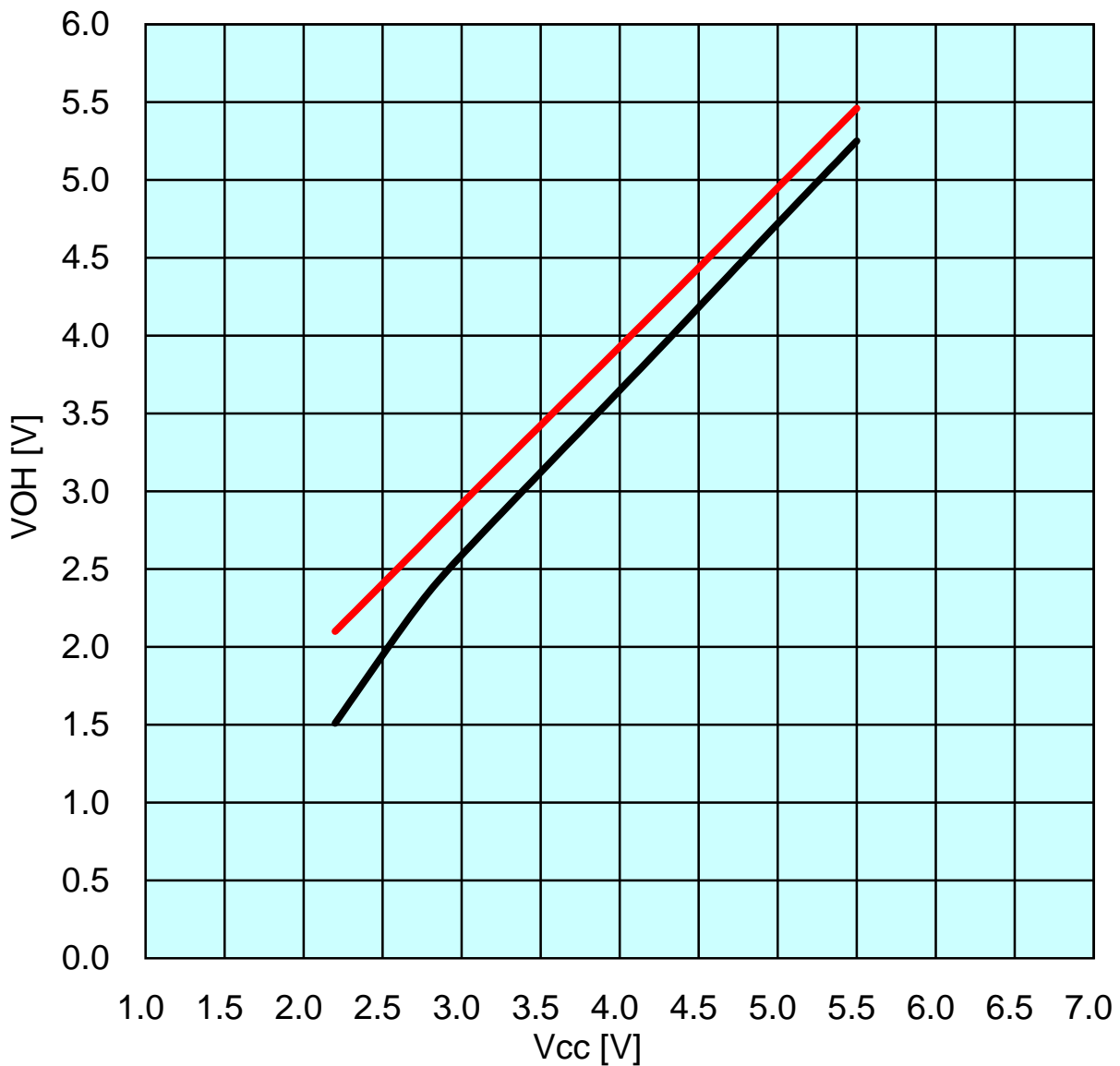

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.