

-I_p VS V_{cc}

**(P0_0-P0_7,P1_0-P1_7,P2_0-P2_7,P3_0,P3_1,
P3_3-P3_5,P3_7,P4_3-P4_5,P6_0-P6_7)**

Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)


R5F21258SDFP(Topr=-40 to 85degrees C)

Pull up MOS=on

— 85degreesC

— 25degreesC

— -40degreesC

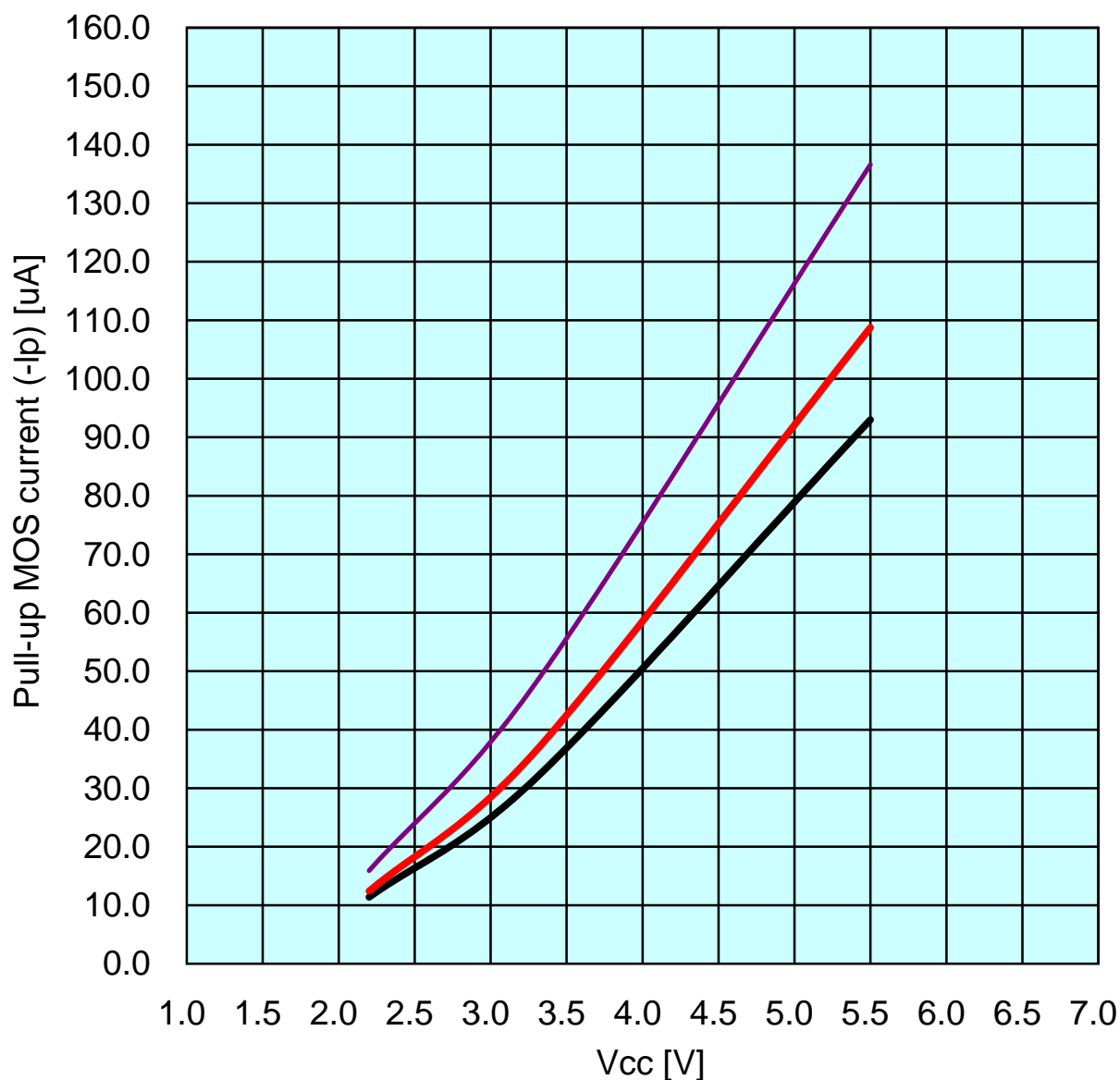

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.