

A/D accuracy 10bit

R8C/26-27 Group

Topr = 25 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=5.12V Vref=2.2V

Xin=20MHz φAD=10MHz sample and hold=on Repeat mode

Absolute accuracy
2.59LSB

Prepared on Sep. 07, 2007

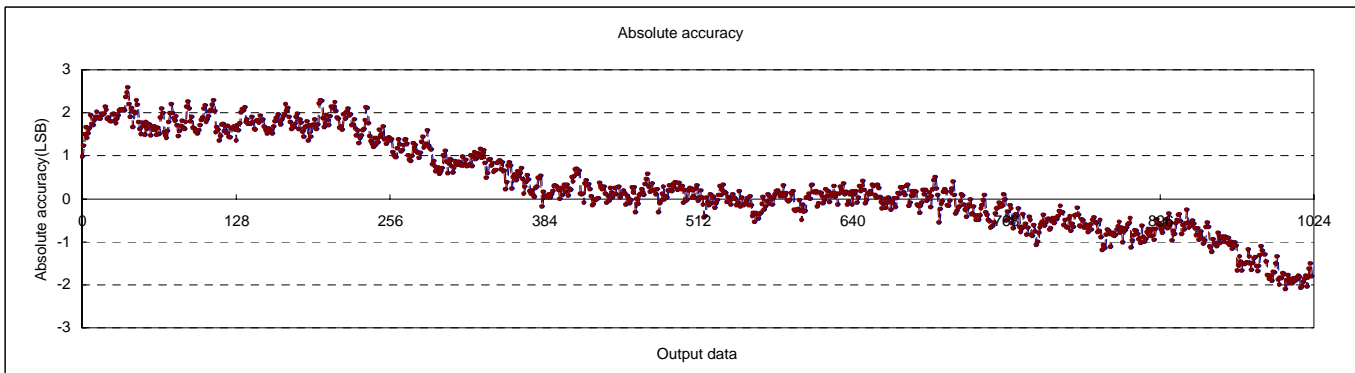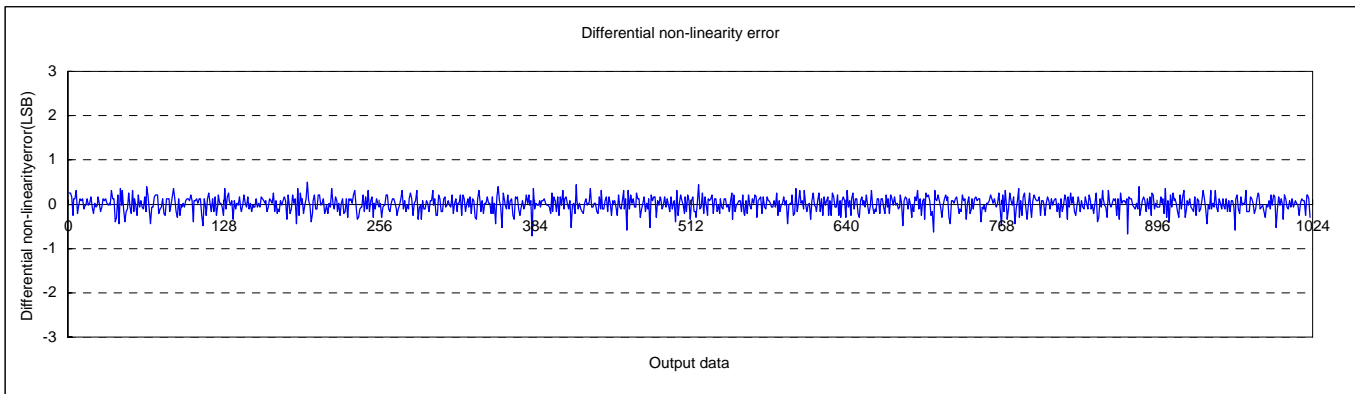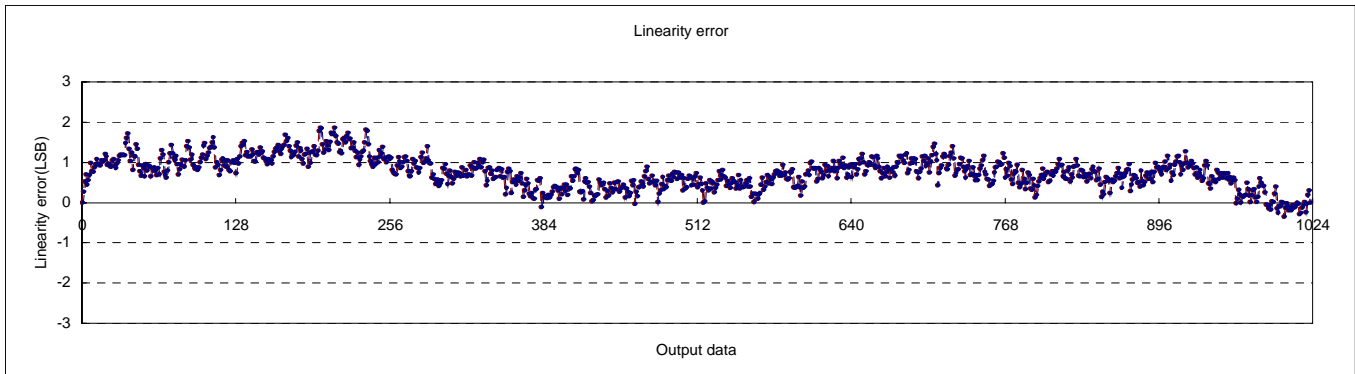

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.