

# A/D accuracy 10bit

R8C/26-27 Group

Topr = 85 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=2.252V

Xin=10MHz  $\phi$ AD=5MHz sample and hold=on Repeat mode

Absolute accuracy  
-1.53LSB

Prepared on Sep. 07, 2007

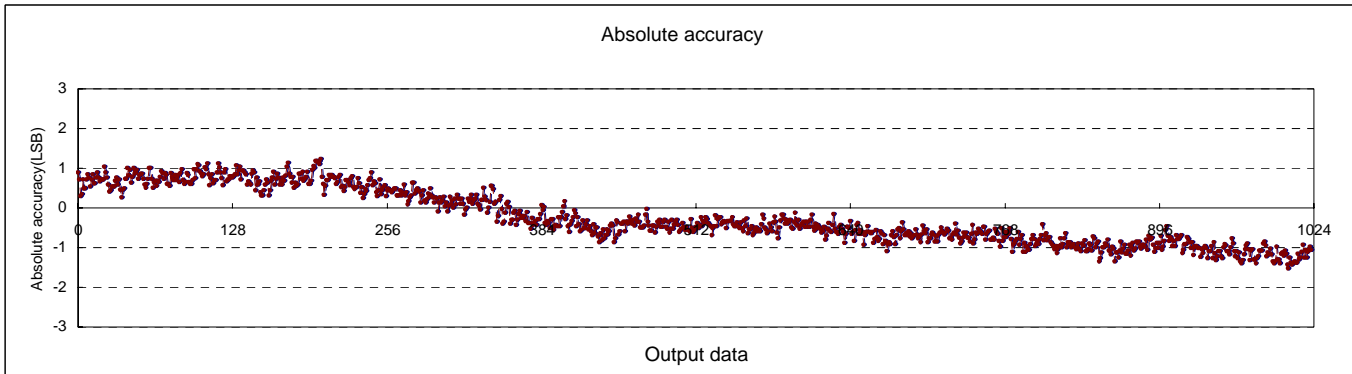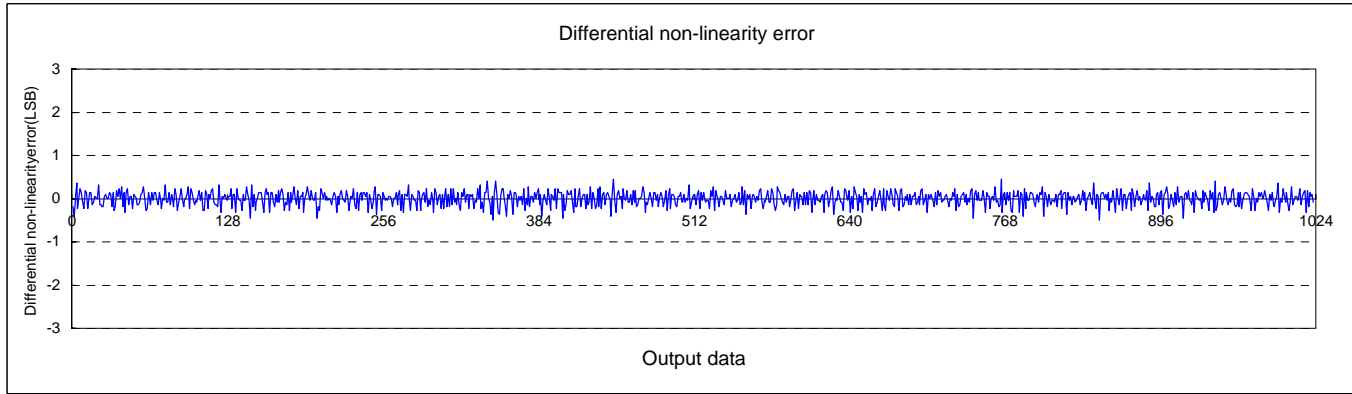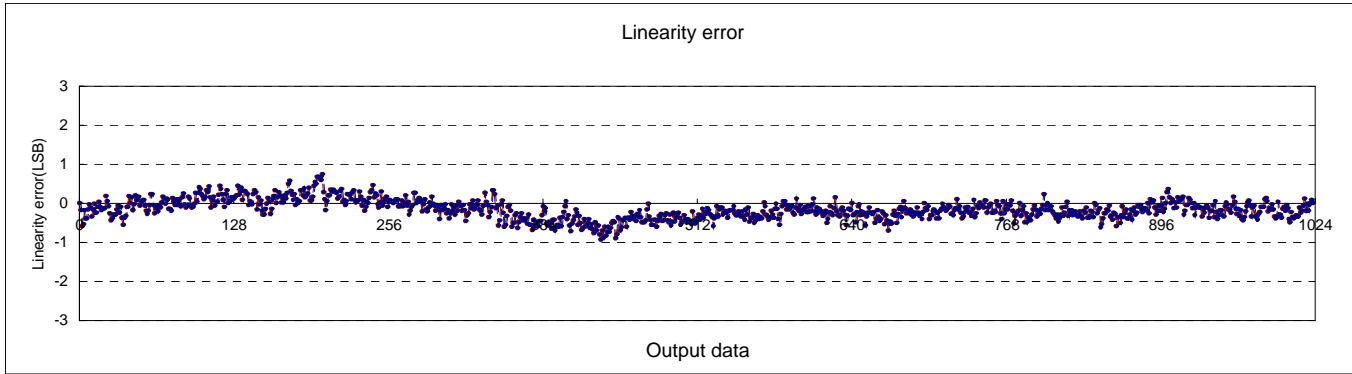

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.