


I_{OH} vs V_{OH} **(P0_0-P0_7, P3_1, P3_3-P3_7, P4_5, P5_3, P5_4)**

Prepared on Sep. 07, 2007

R8C/26-27 Group
V_{CC} = 5.0V

— 85 degrees C — 25 degrees C
— -40 degrees C

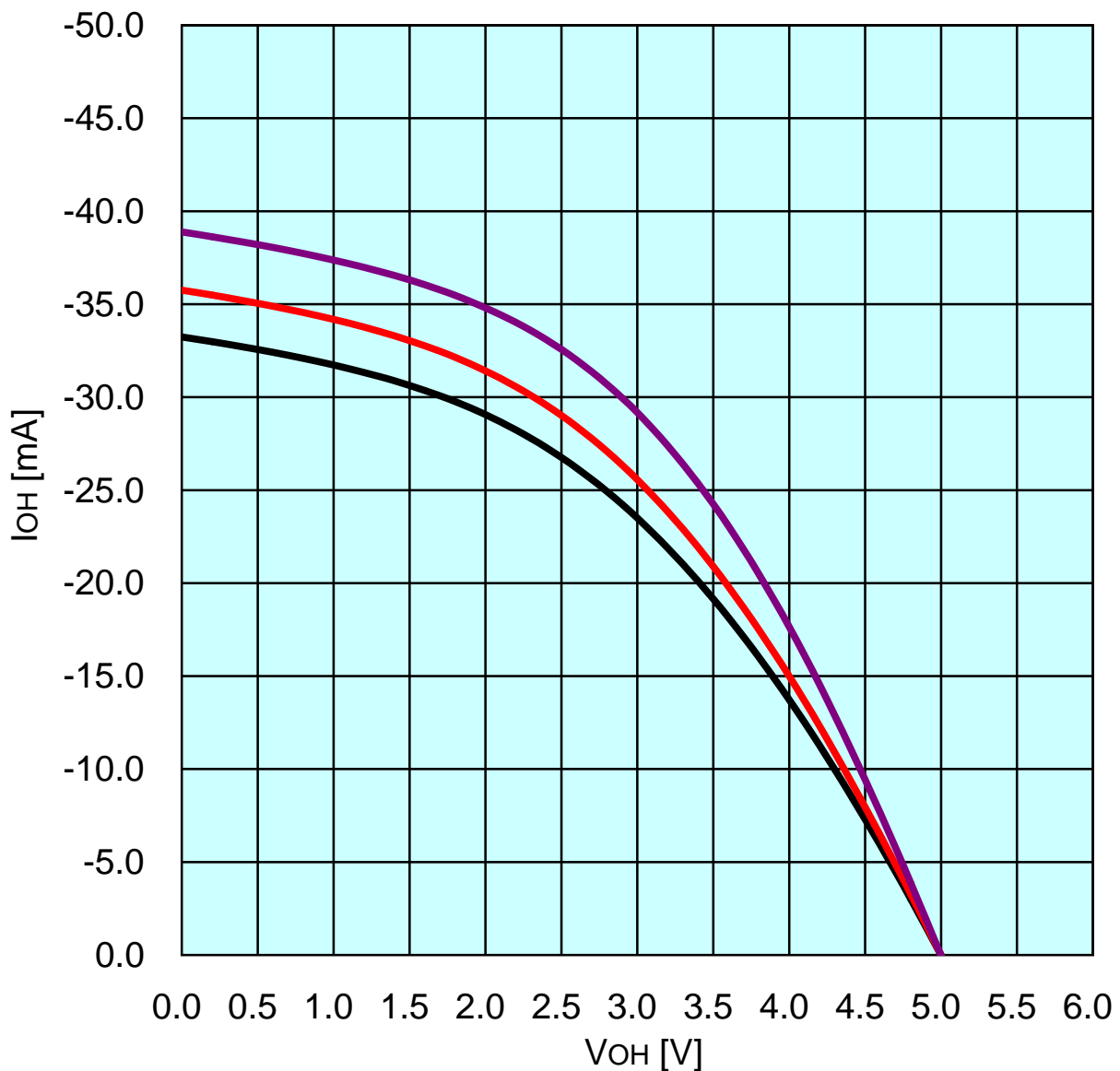

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.