


# IOH vs VOH

(P0\_0 to P0\_3,P0\_5,P1\_0 to P1\_7,P3\_3 to P3\_5,P4\_5)

Prepared on Feb. 14, 2008

R8C/2K Group  
Vcc=2.2V

— 85degreesC    — 25degreesC  
— -40degreesC

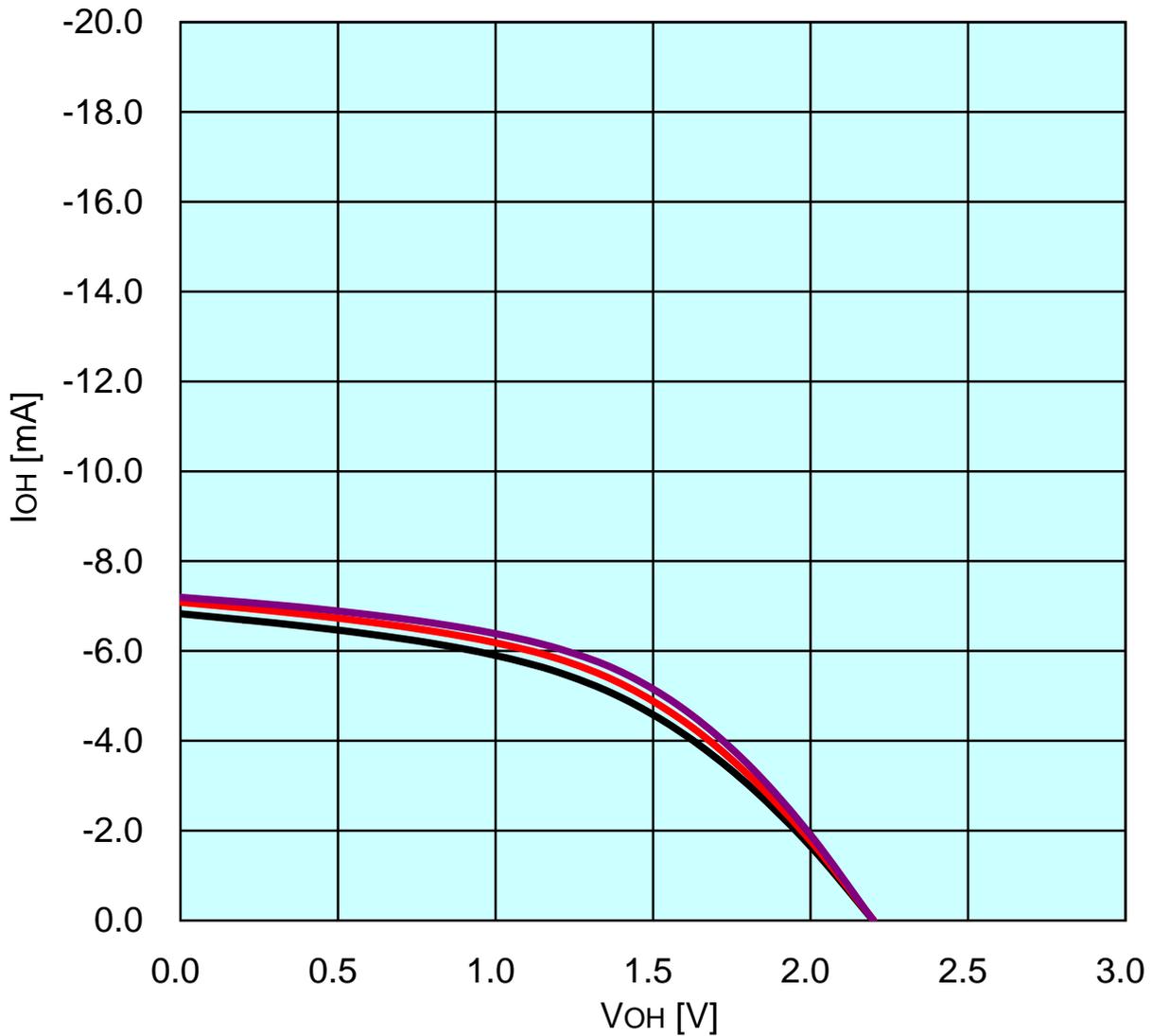

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.