

# Frequency vs Topr (Low-speed on-chip oscillator mode)


Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)  
R5F21258SDFP(Topr=-40 to 85degrees C)  
Low-speed on-chip oscillator on

— VCC=5.0V

— VCC=3.0V

— VCC=2.2V

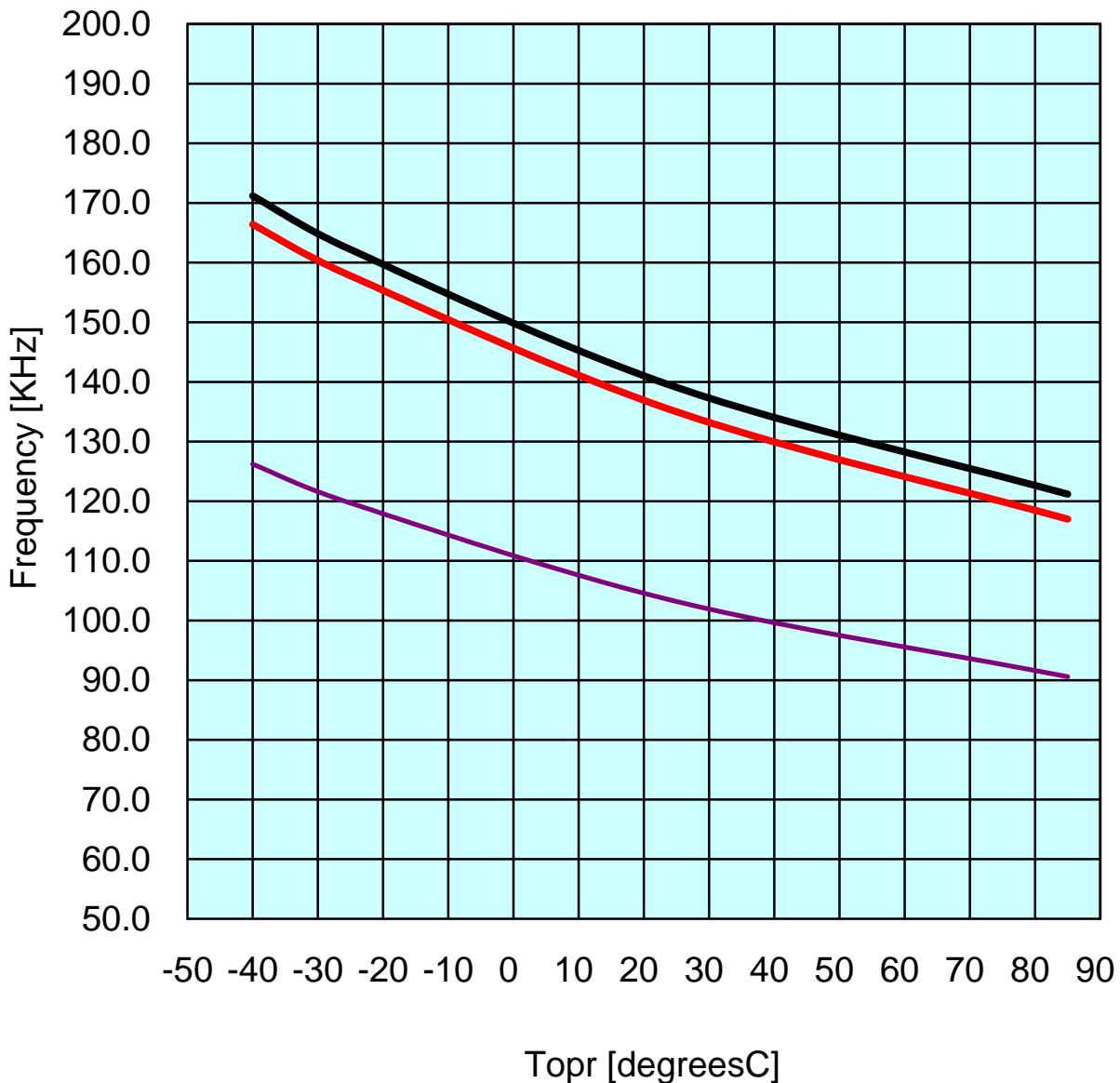

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.