

# A/D accuracy 10bit

R8C/2A-2D Group




Topr = 85 degrees C

AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=3.379V

Xin=20MHz  $\phi_{AD}$ =10MHz sample and hold=on Repeat mode

|                              |
|------------------------------|
| Absolute accuracy<br>2.49LSB |
|------------------------------|

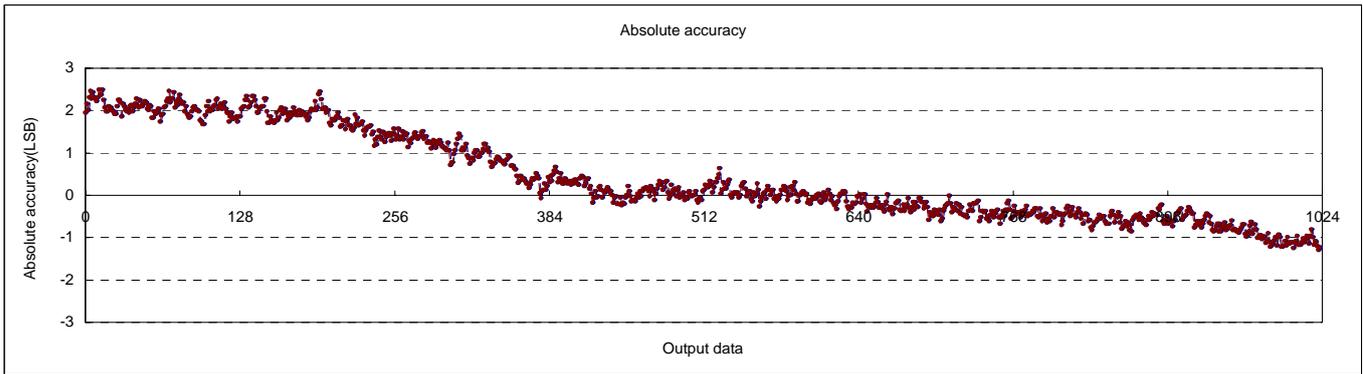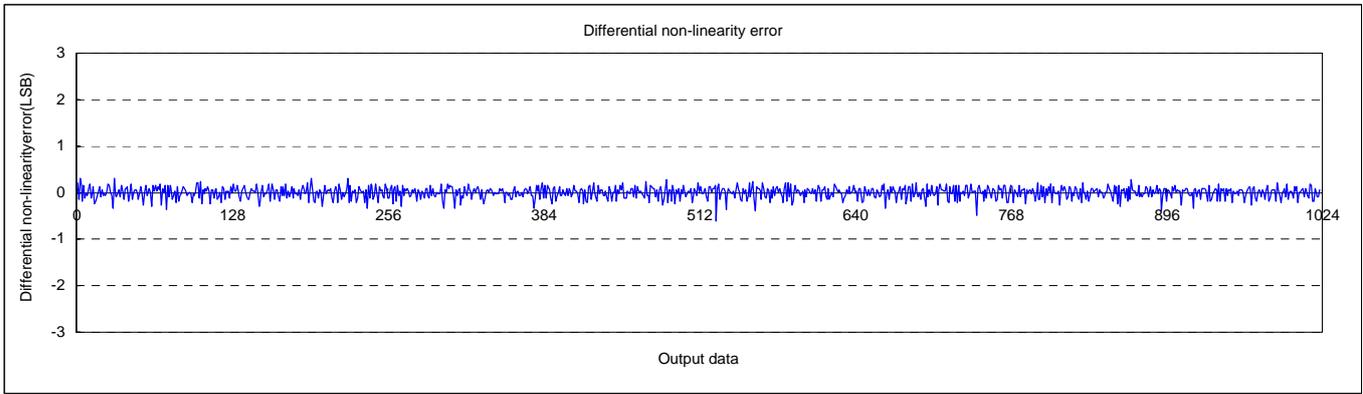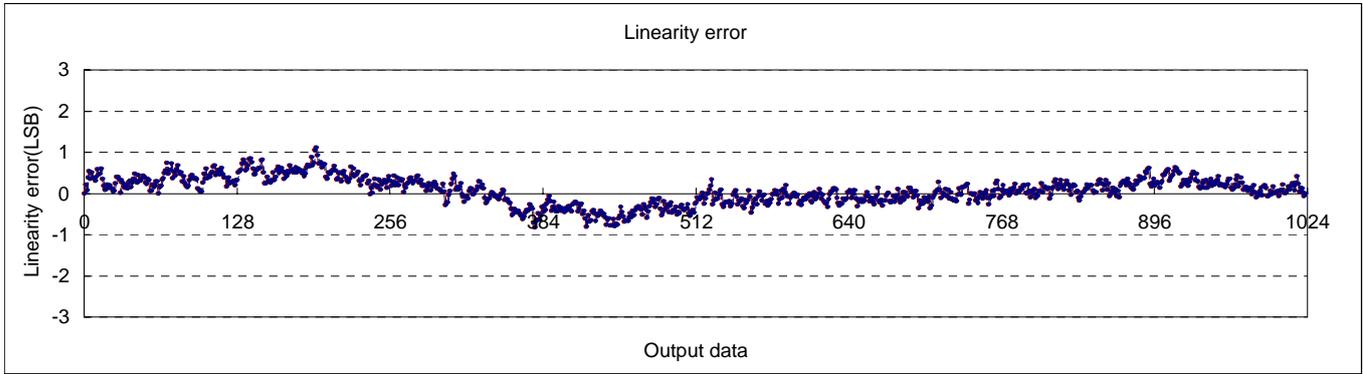

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.