

A/D accuracy 10bit

R8C/2A-2D Group




Topr = 85 degrees C

AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=2.252V

Xin=10MHz ϕ_{AD} =5MHz sample and hold=on Repeat mode

Absolute accuracy
-1.53LSB

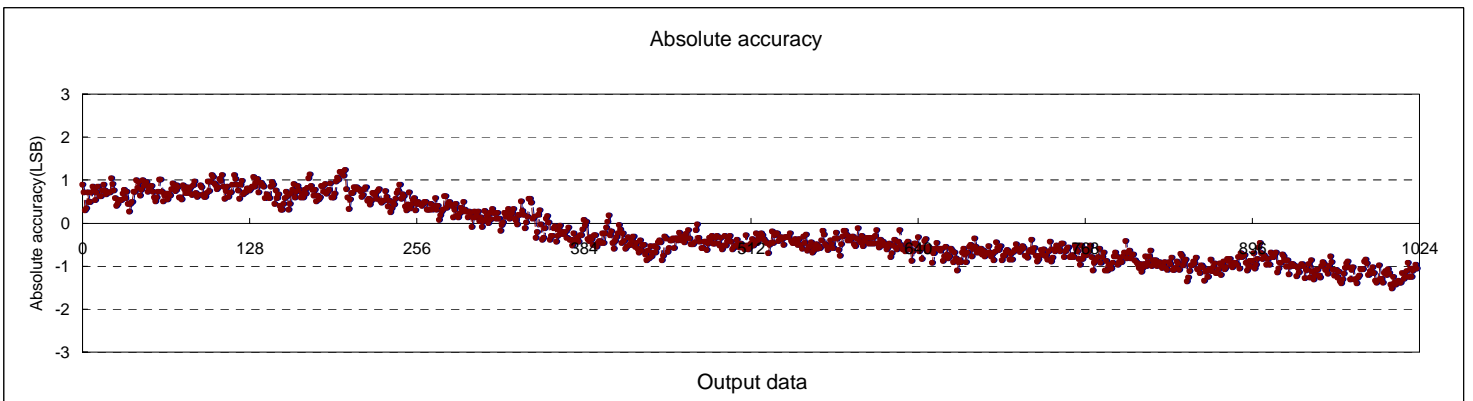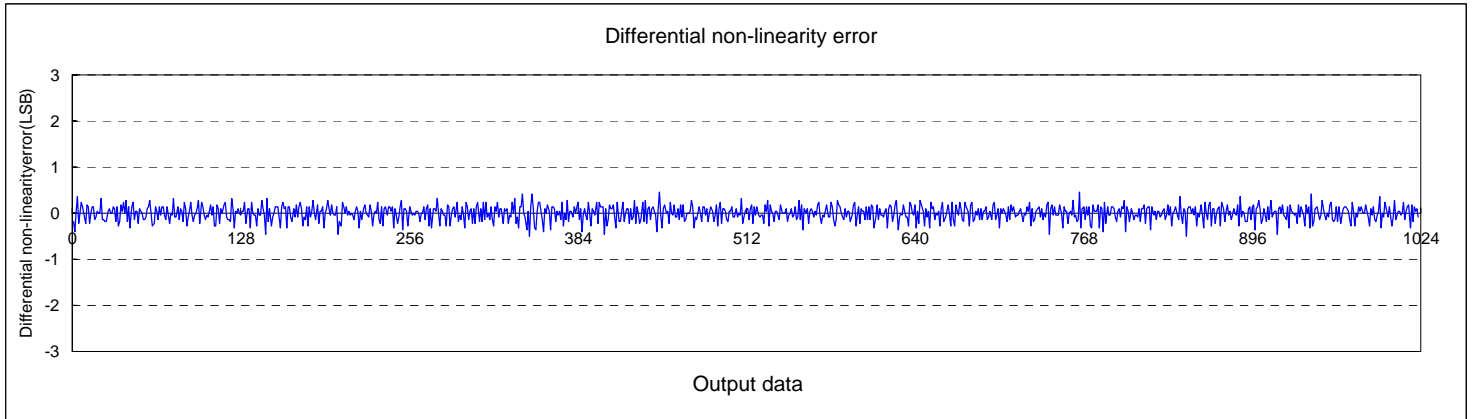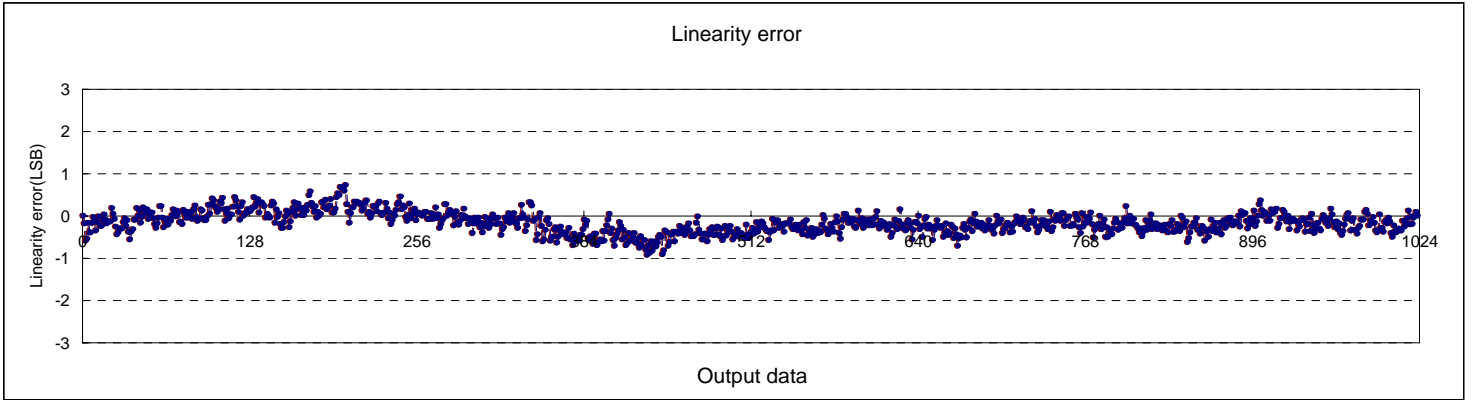

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.