

# IOH vs VOH

(P0\_0-P0\_7,P1\_0-P1\_7,P3\_0,P3\_1,  
P3\_3-P3\_5,P3\_7,P4\_2-P4\_5,P6\_0-P6\_7)

Prepared on Oct. 20, 2006


R5F21248SNFP (Topr=-20 to 85degrees C)

R5F21248SDFP (Topr=-40 to 85degrees C)

Topr=25degrees Celsius

Vcc=5V, 3V, 2.2V

— Vcc=5V — Vcc=3V — Vcc=2.2V

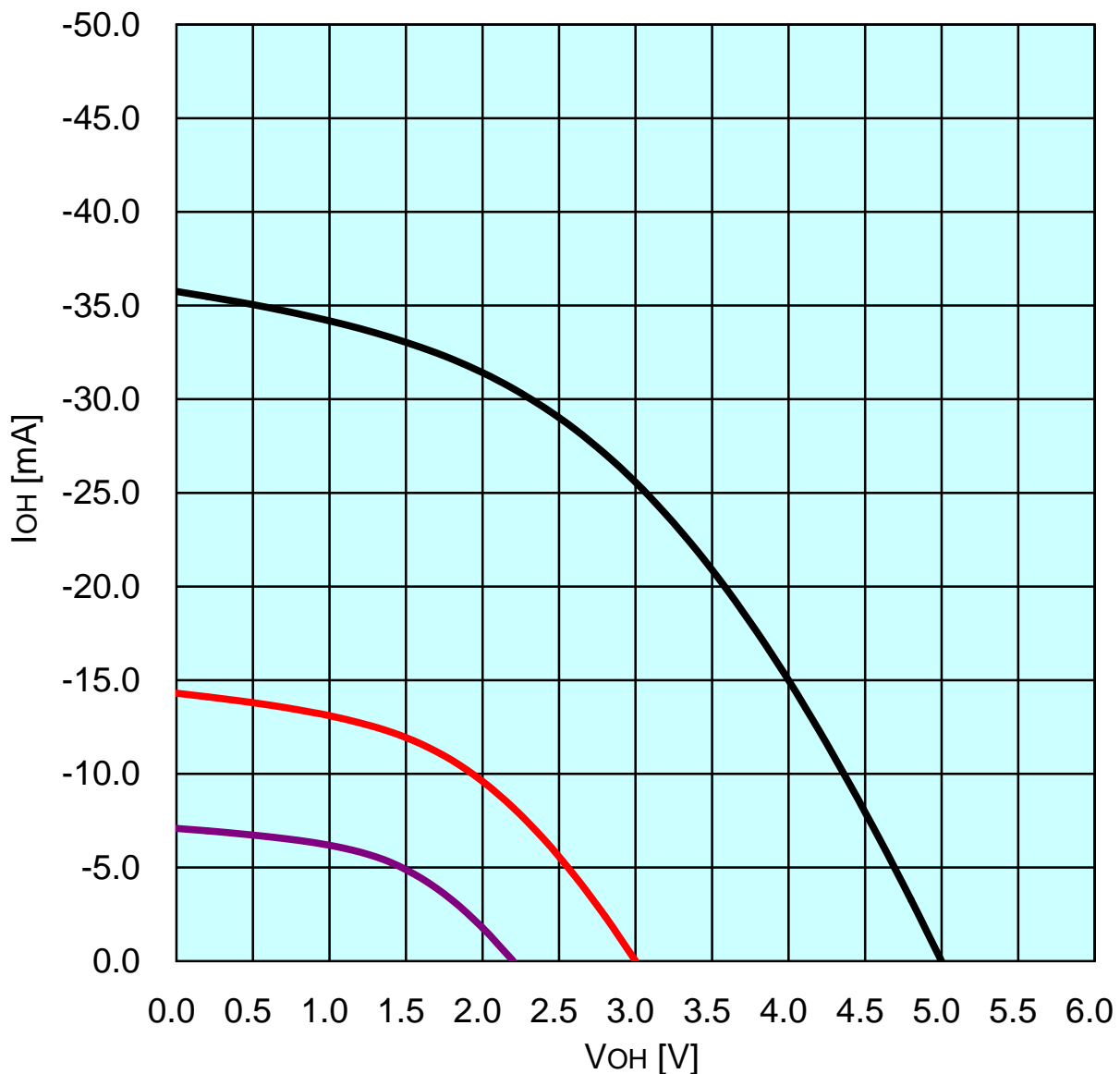

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.