

IOH vs VOH (P2_0-P2_7 Drive Capacity=High)


Prepared on Oct. 20, 2006

R5F21248SNFP (Topr=-20 to 85degrees C)
R5F21248SDFP (Topr=-40 to 85degrees C)
Vcc=3V

— 85degreesC

— 25degreesC

— -40degreesC

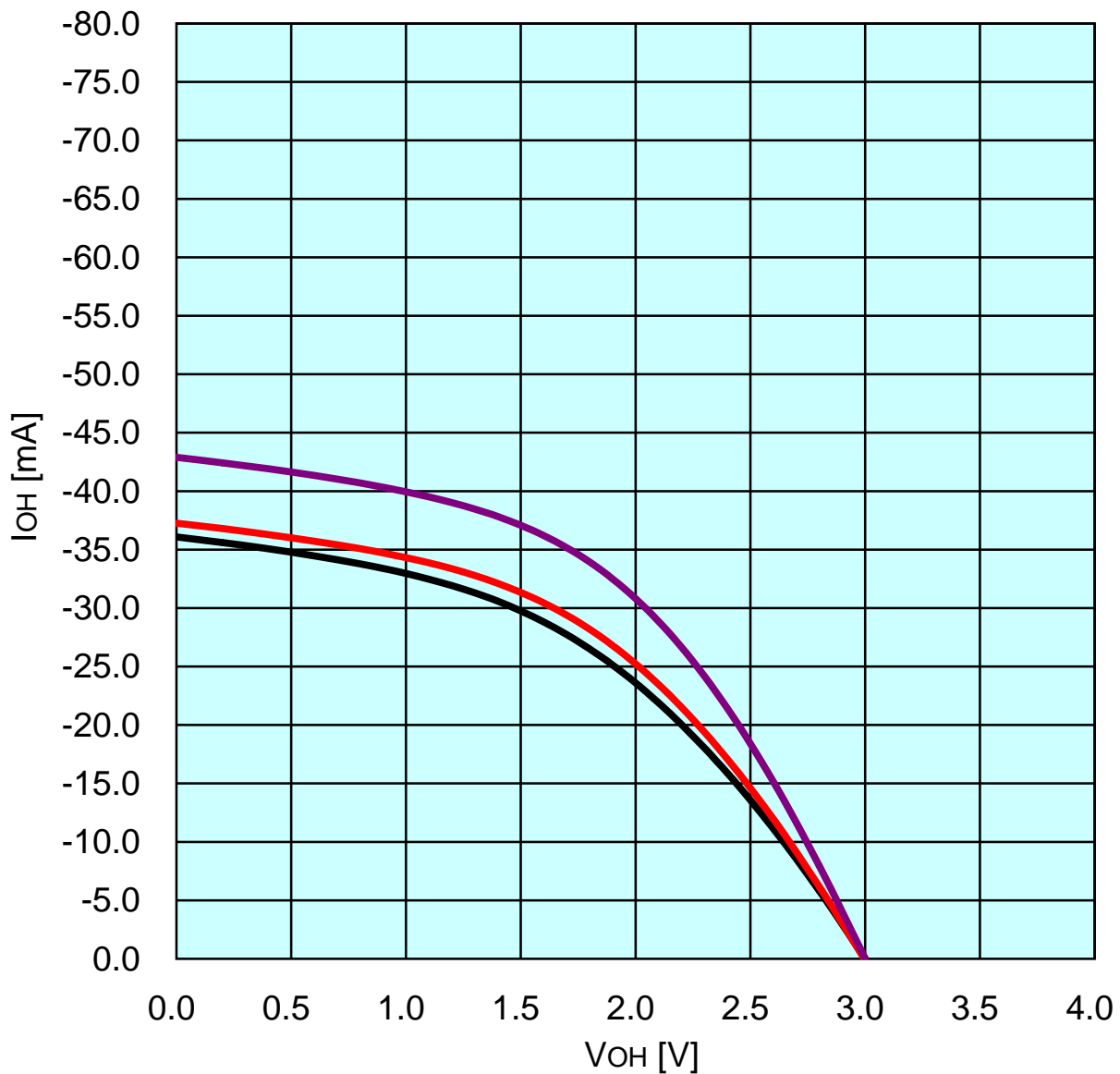

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.