

IoL vs VOL

(P2_0-P2_7 Drive Capacity=High)

Prepared on Oct. 20, 2006

R5F21248SNFP (Topr=-20 to 85degrees C)


R5F21248SDFP (Topr=-40 to 85degrees C)

Vcc=2.2V

— 85degreeC

— 25degreeC

— -40degreeC

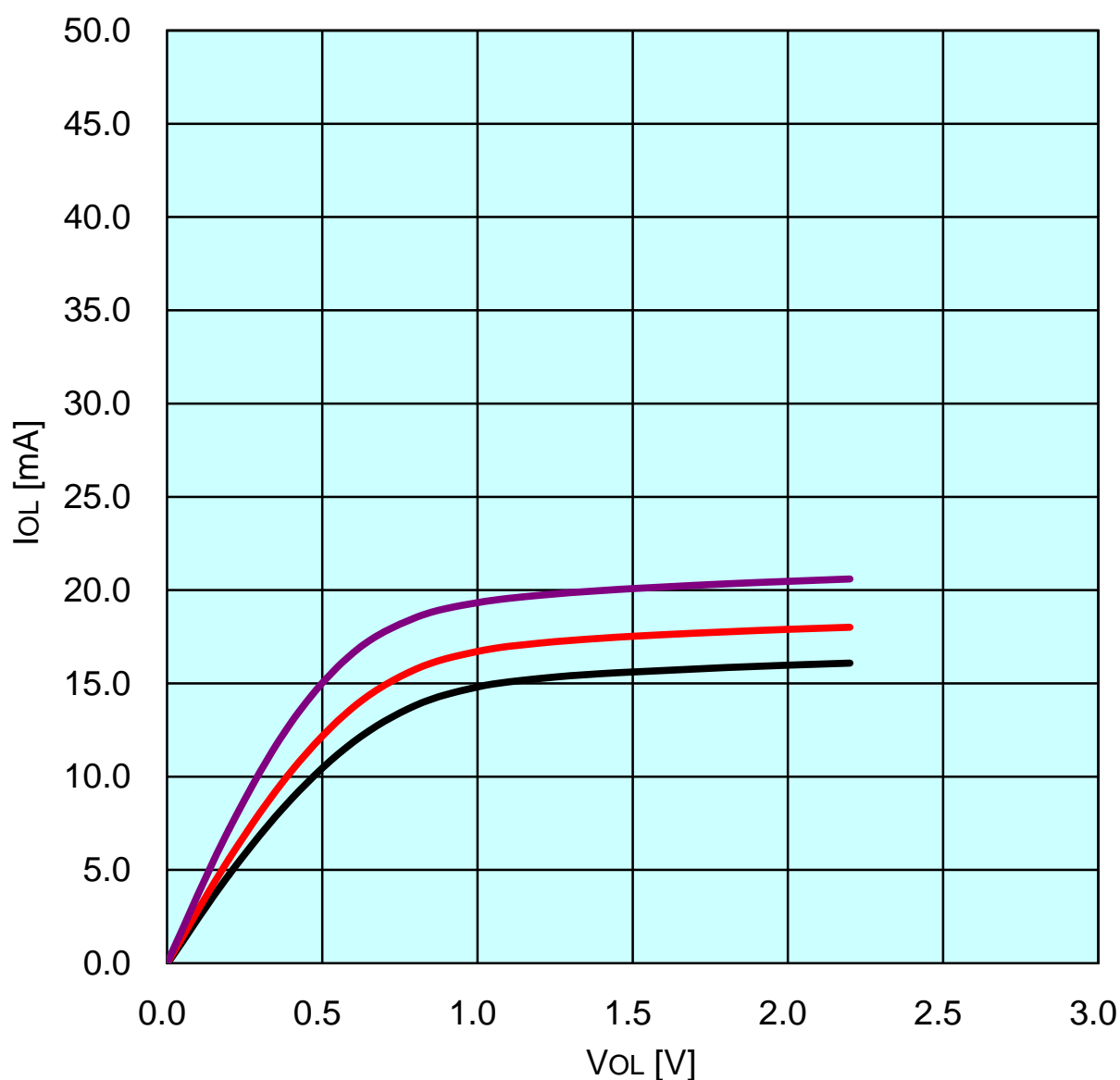

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.