

# VOH vs VCC

(P2\_0-P2\_7 Drive Capacity=High)


Prepared on Oct. 20, 2006

R5F21248SNFP (Topr=-20 to 85degrees C)  
R5F21248SDFP (Topr=-40 to 85degrees C)  
Topr=25degrees C  
IOH=-20mA, -5mA, -2mA

— IOH=-20mA

— IOH=-5mA

— IOH=-2mA

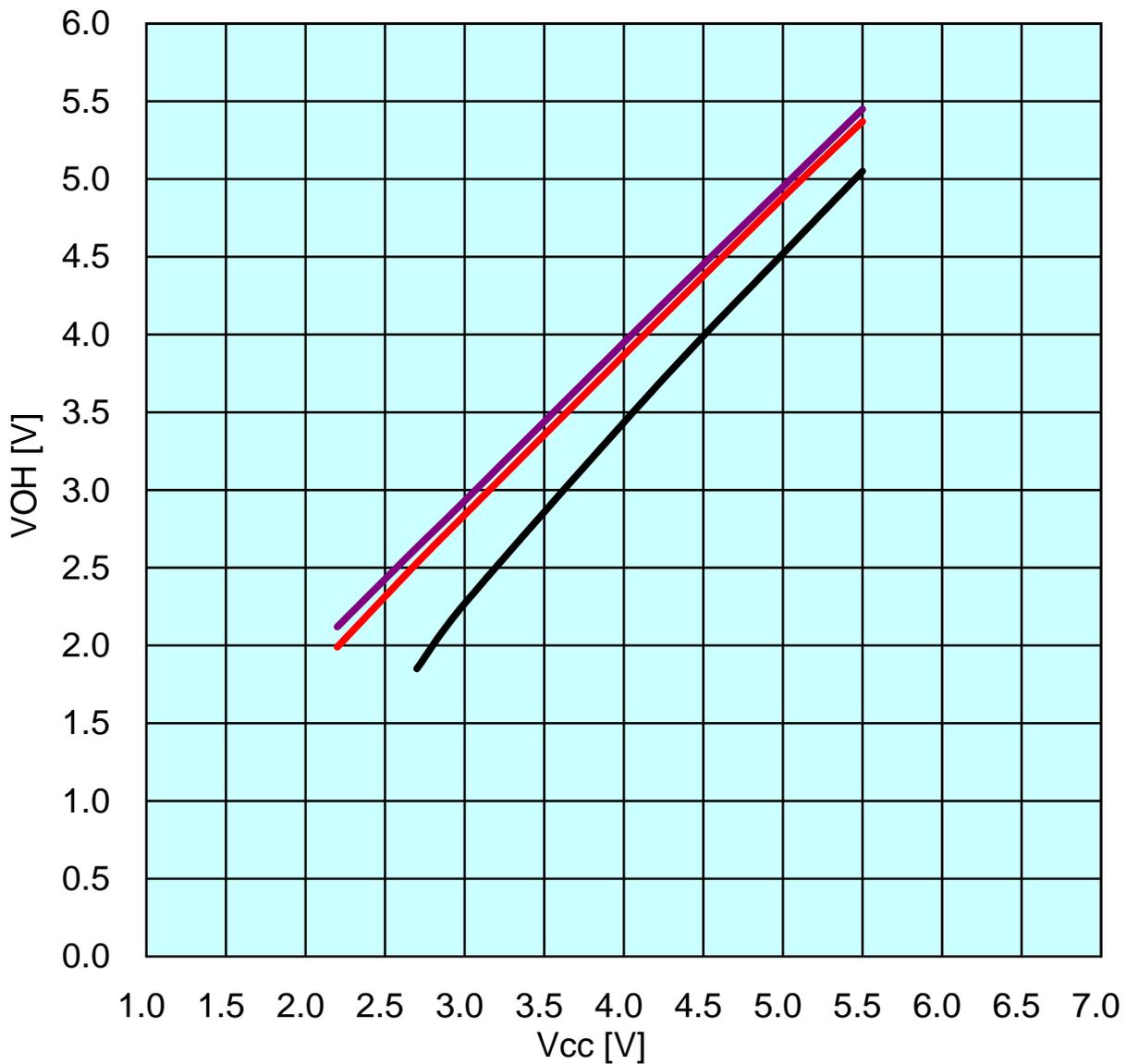

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.