

VOH vs VCC


(P2_0-P2_7 Drive Capacity=Low)

Prepared on Oct. 20, 2006

R5F21248SNFP (Topr=-20 to 85degrees C)
R5F21248SDFP (Topr=-40 to 85degrees C)
Topr=25degrees C
IOH= -5mA, -1mA

— IOH=-5mA

— IOH=-1mA

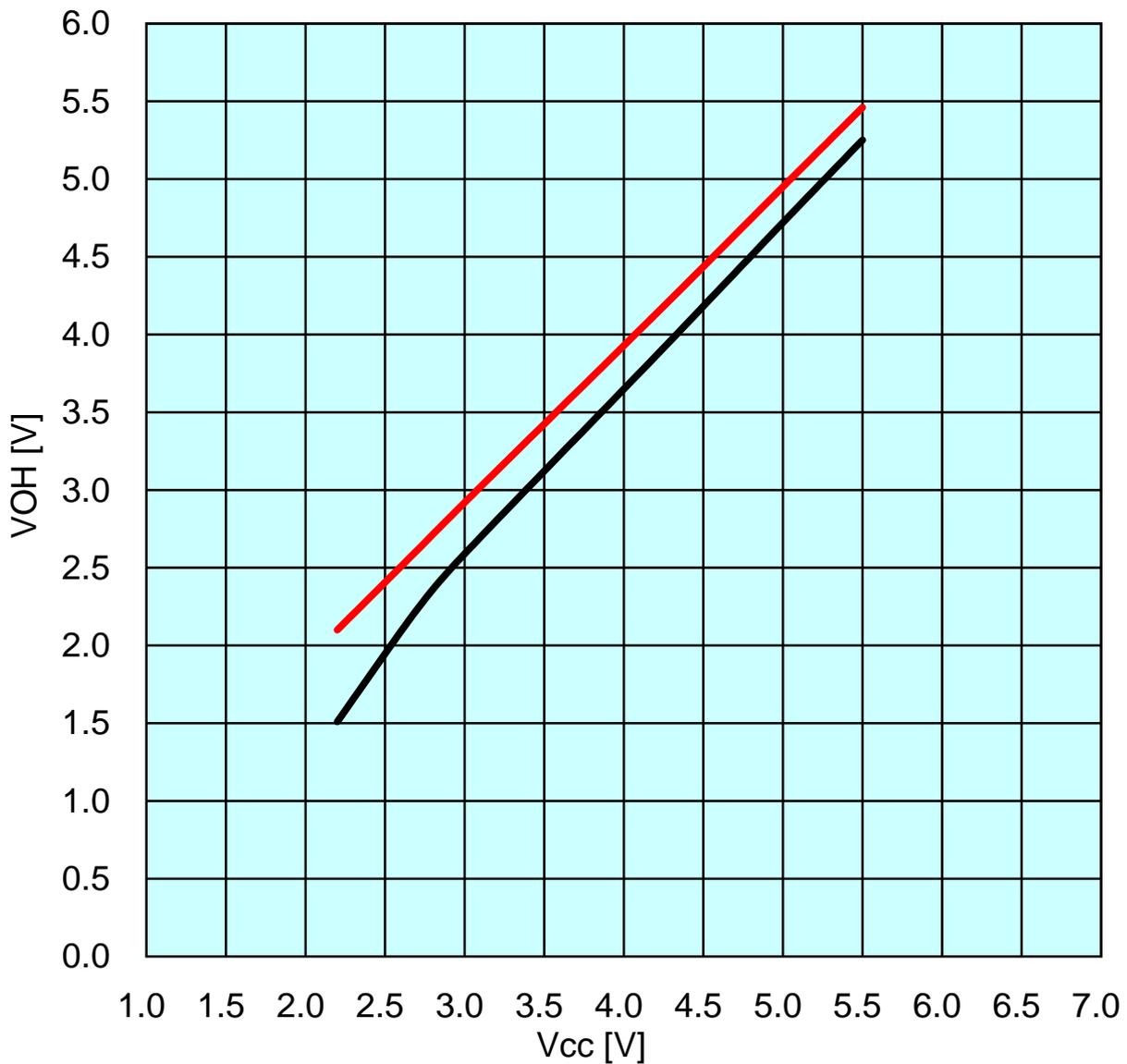

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.